


Product data sheet

Characteristics

ZC2JE65

Limit switch head, Limit switches XC Standard, ZC2J, side steel roller plunger vertical

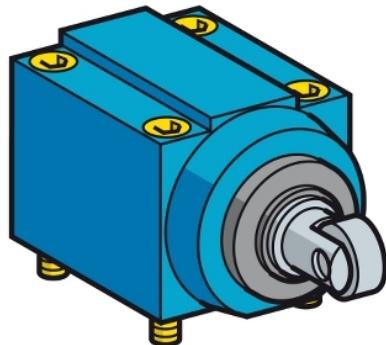

Main

Range of Product	OsiSense XC
Series name	Special format
Product or Component Type	Limit switch head
Device short name	ZC2J
Head type	Plunger head
Product Compatibility	XC2J
Associated body	ZC2JC2 ZC2JD2 ZC2JC28 ZC2JC18 ZC2JC1 ZC2JD1
Movement of operating head	Linear
Type of operator	Side roller plunger spring return metal with vertical roller)
Type of approach	Lateral approach, 2 directions

Complementary

Switch actuation	By 30° cam
Positive opening	Without
Net Weight	0.54 lb(US) (0.245 kg)
Head material	Metal

Environment

Ambient Air Temperature for Operation	-13...158 °F (-25...70 °C)
Ambient Air Temperature for Storage	-40...158 °F (-40...70 °C)
Environmental characteristic	Standard environment

Ordering and shipping details

Category	22449-LIMIT SWITCHES,ACCESSORIES
Discount Schedule	T
GTIN	3389110324167
Returnability	No
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.97 in (5.0 cm)
Package 1 Width	3.70 in (9.4 cm)
Package 1 Length	1.89 in (4.8 cm)
Package 1 Weight	8.89 oz (252.0 g)
Unit Type of Package 2	S01
Number of Units in Package 2	14
Package 2 Height	5.91 in (15.0 cm)
Package 2 Width	5.91 in (15.0 cm)

Package 2 Length	15.75 in (40.0 cm)
Package 2 Weight	8.26 lb(US) (3.745 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Diisobutyl phthalate (DINP), which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	 REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------