


MPO w/ pins to LC fanout fiber optic cable assembly, 0.9mm diameter, 12 fiber, OS2 9/125µm Single Mode, 5 meter

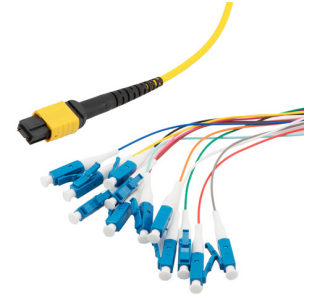

## MPM12OS2-09LCR-5

### Features

- 12 Fiber MPO w/ pins (male) to LC Fan-out for server-to-switch and other link aggregation
- 3mm Diameter OFNP (Plenum Rated) Jacket complies with strict building codes
- Single mode OS2 9/125µm cabling for aggregation of links
- Fully compatible with US Conec MTP products

### Applications

- Ethernet
- LAN
- Server Farms
- Voice/Video/Data

### Description

The MPM12OS2-09LCR-5 from L-com is a fan-out cable assembly that comes with an MPO (w/ pins) to LC/UPC connector configuration. This fiber optic cable features an OFNP-rated PVC jacket and has a cable diameter of 3 mm. Our fan-out cable is suitable for applications such as Ethernet, LAN, server farms, and voice/video/data. This yellow fiber optic cable assembly is available in a length of 5 meters and can withstand temperatures ranging from -10 to 60 degrees C.

Our MPO (w/ pins) male to LC cable comes with a single mode OS2 fiber and has a fiber diameter of 9/125 µm. L-com's MPM12OS2-09LCR-5 fan-out cable assembly has a breakout diameter of 0.9 mm and is ideal for making connections within rack mounted or wall mounted fiber enclosures. Our fiber optic cable assembly can be customized in different lengths to fit specific installation needs, ensuring efficient network management in high-density setups without compromising delivery time or quality. Additional dimensions, specifications, and CAD drawings for this 12 fiber cable can be found on its downloadable PDF datasheet.

L-com has one of the largest in-stock selections of fiber optic cable assemblies for international and domestic orders. Make your online purchase right now to take advantage of our same-business-day shipping. We are committed to delivering excellent service to support our customers in maintaining the continuity and reliability of their networks. For further information on similar products, our expert technical support and knowledgeable sales team can help you get the ideal single mode OS2 fan-out cable for your requirements.


### Configuration

|                     |                     |
|---------------------|---------------------|
| Function            | Fan-out             |
| Cable Type          | Base-12 Single Mode |
| Mode                | Single Mode         |
| Mode Class          | OS2                 |
| Fiber Diameter      | 9/125 µm            |
| Connection 1 Type   | MPO (w/ pins)       |
| Connection 1 Gender | Male                |
| Connection 1 Polish | APC                 |
| Connection 2 Type   | LC                  |
| Connection 2 Polish | UPC                 |
| Cable Color         | Yellow              |

### Optical Specifications

| Description                  | Minimum | Typical | Maximum | Units |
|------------------------------|---------|---------|---------|-------|
| Return Loss - MPO            | 60      |         |         | dB    |
| Insertion Loss - MPO         |         |         | 0.35    | dB    |
| Return Loss - LC, ST, SC, FC | 50      |         |         | dB    |

MPO w/ pins to LC fanout fiber optic cable assembly, 0.9mm diameter, 12 fiber, OS2 9/125µm Single Mode, 5 meter

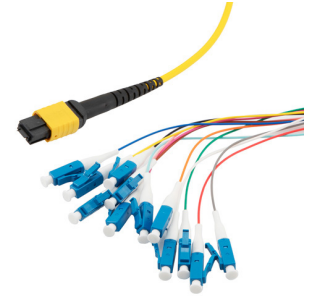

## MPM12OS2-09LCR-5

### Optical Specifications

| Description                     | Minimum | Typical | Maximum | Units |
|---------------------------------|---------|---------|---------|-------|
| Insertion Loss - LC, ST, SC, FC |         |         | 0.3     | dB    |

### Mechanical Specifications

#### Cable Assembly

|                |                     |
|----------------|---------------------|
| Length         | 5 m [196.85 in]     |
| Width/Diameter | 3 mm                |
| Weight         | 340.19 g [0.75 lbs] |

#### Cable

|                                            |         |
|--------------------------------------------|---------|
| Cable Type                                 | Fan-out |
| Polarity                                   | NEUTRAL |
| Breakout Diameter                          | 0.9 mm  |
| Static Bend Radius                         | 30 mm   |
| Dynamic Bend Radius                        | 60 mm   |
| Max Crush Resistance, Short Term (N/100mm) | 400     |
| Max Crush Resistance, Long Term (N/100mm)  | 100     |

### Connectors

| Description      | Connector 1        | Connector 2 |
|------------------|--------------------|-------------|
| Type             | MPO (w/ pins) Male | LC          |
| Configuration    | Straight           | Straight    |
| Connector Polish | APC                | UPC         |

### Environmental Specifications


|                                |                  |
|--------------------------------|------------------|
| Operating Range Temperature    | -10 to +60 deg C |
| Storage Range Temperature      | -10 to +70 deg C |
| Ingress Protection (IP) Rating | Non-Rated        |

**Compliance Certifications** (see [product page](#) for current document)

### Plotted and Other Data

Notes:

MPO w/ pins to LC fanout fiber optic cable assembly, 0.9mm diameter, 12 fiber, OS2 9/125µm Single Mode, 5 meter

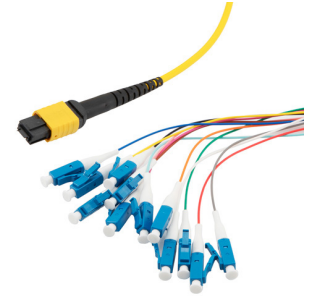

## MPM12OS2-09LCR-5

### Typical Performance Data

### How to Order

|                            |                       |            |           |                                                  |
|----------------------------|-----------------------|------------|-----------|--------------------------------------------------|
| Part Number Configuration: | <b>MPM12OS2-09LCR</b> | <b>-XX</b> | <b>UU</b> |                                                  |
|                            |                       |            |           | Unit of Measure:<br>F = Feet<br><blank> = Meters |
|                            |                       |            |           | Lengths                                          |
|                            |                       |            |           | Base Number                                      |

Example: MPM12OS2-09LCR-12 = 12 meters long cable  
MPM12OS2-09LCR-10F = 10 feet long cable

MPO w/ pins to LC fanout fiber optic cable assembly, 0.9mm diameter, 12 fiber, OS2 9/125µm Single Mode, 5 meter from L-com has same day shipment for domestic and International orders. Our portfolio includes coaxial cable assemblies, connectors, adapters and custom products as well as lightning and surge protectors, NEMA rated enclosures, and an RF product line which includes antennas, amplifiers, passive, and active components.

URL: <https://www.l-com.com/mpo-pins-lc-fan-out-0.9mm-diameter-12-fiber-os2-9-125um-single-mode-ofnp-jacket-aqua-5-meter-mpm12os2-09lcr-5>

The information contained within this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part in order to impliment improvements. L-com reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. L-com does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and L-com does not assume liability arising out of the use of any part or document.

MPM12OS2-09LCR-5 CAD Drawing

MPO w/ pins to LC fanout fiber optic cable assembly, 0.9mm diameter, 12 fiber, OS2 9/125µm Single Mode, 5 meter

