


Fiber Patch Cable MPO Male to MPO Male, 12 Fiber SMF Type A, LSZH (Low Smoke, Zero Halogen) Rated, 1-Meter

MPMM12SMAZ-1

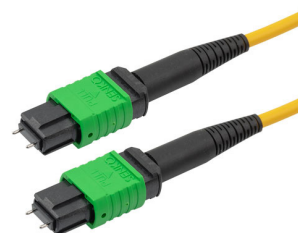

Features

- Fiber Optic Patch Cable Assembly
- MPO Male to MPO Male
- Cable Type: Single Mode
- Cable Jacket: LSZH (Low Smoke, Zero Halogen) rated
- Cable Length: 1 meter

Applications

- Ethernet
- LAN
- Server Farms
- Voice/Video/Data

Description

L-com's MPMM12SMAZ-1 is a fiber optic patch cable assembly that is suitable for Ethernet, LAN, server farms, and voice/video/data applications. This yellow fiber optic cable is equipped with MPO (w/ pins) male to MPO (w/ pins) male connectors. Our patch cable assembly has a type A (key up, key down) polarity. This fiber optic cable assembly is available in a length of 1 meter.

This MPO (w/ pins) male to MPO (w/ pins) male cable comes with a single mode fiber and has a fiber diameter of 9/125µm. The MPMM12SMAZ-1 fiber optic patch cable from L-com features an LSZH-rated jacket. Our fiber optic cable assembly can be customized in different lengths to fit specific installation needs, ensuring efficient network management in high-density setups without compromising delivery time or quality. Additional dimensions, specifications, and CAD drawings for this cable can be found on its downloadable PDF datasheet.

L-com has one of the largest in-stock selections of fiber optic patch cables for international and domestic orders. Make your online purchase right now to take advantage of our same-business-day shipping. We are committed to delivering excellent service to support our customers in maintaining the continuity and reliability of their networks. For further information on similar products, our expert technical support and knowledgeable sales team can help you get the ideal single mode fiber optic cable for your requirements.

Configuration

Function	Patch
Cable Type	Base-12 Single Mode
Mode	Single Mode
Mode Class	OS2
Fiber Diameter	9/125 µm
Connection 1 Type	MPO (w/ pins)
Connection 1 Gender	Male
Connection 1 Polish	APC
Connection 2 Type	MPO (w/ pins)
Connection 2 Gender	Male
Connection 2 Polish	APC
Cable Color	Yellow


Optical Specifications

Description	Minimum	Typical	Maximum	Units
Return Loss - MPO	60			dB
Insertion Loss - MPO			0.5	dB

Mechanical Specifications

Cable Assembly	
Length	1 m [39.37 in]

Fiber Patch Cable MPO Male to MPO Male, 12 Fiber SMF Type A, LSZH (Low Smoke, Zero Halogen) Rated, 1-Meter

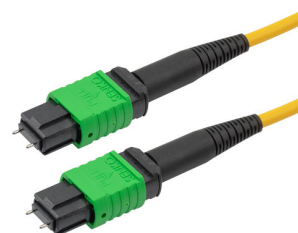

MPMM12SMAZ-1

Width/Diameter	3 mm
Cable	
Cable Type	Patch
Polarity	Type A
Static Bend Radius	30 mm
Dynamic Bend Radius	60 mm
Max Crush Resistance, Short Term (N/100mm)	500
Max Crush Resistance, Long Term (N/100mm)	100

Connectors

Description	Connector 1	Connector 2
Type	MPO (w/ pins) Male	MPO (w/ pins) Male
Configuration	Straight	Straight
Connector Polish	APC	APC

Environmental Specifications


Operating Range Temperature	-20 to +70 deg C
Storage Range Temperature	-40 to +70 deg C

Compliance Certifications (see [product page](#) for current document)

Plotted and Other Data

Notes:

Fiber Patch Cable MPO Male to MPO Male, 12 Fiber SMF Type A, LSZH (Low Smoke, Zero Halogen) Rated, 1-Meter

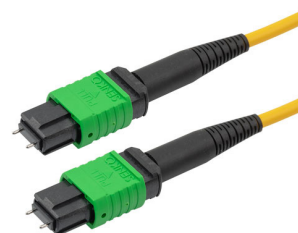

MPMM12SMAZ-1

Typical Performance Data

How to Order

Part Number Configuration:

MPMM12SMAZ

-XX

UU

Unit of Measure:

F = Feet

<blank> = Meters

Lengths

Base Number

Example: MPMM12SMAZ-12 = 12 meters long cable
MPMM12SMAZ-10F = 10 feet long cable

Fiber Patch Cable MPO Male to MPO Male, 12 Fiber SMF Type A, LSZH (Low Smoke, Zero Halogen) Rated, 1-Meter from L-com has same day shipment for domestic and International orders. Our portfolio includes coaxial cable assemblies, connectors, adapters and custom products as well as lightning and surge protectors, NEMA rated enclosures, and an RF product line which includes antennas, amplifiers, passive, and active components.

URL: <https://www.l-com.com/fiber-patch-cable-mpo-male-mpo-male-12-fiber-smf-type-a-lszh-rated-1-meter-mpmm12smaz-1>

The information contained within this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part in order to implement improvements. L-com reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. L-com does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and L-com does not assume liability arising out of the use of any part or document.

Fiber Patch Cable MPO Male to MPO Male, 12 Fiber SMF Type A, LSZH (Low Smoke, Zero Halogen) Rated, 1-Meter