

3ft (1m) USB to Serial Cable with COM Port Retention, DB9 Male RS232 to USB Converter, USB to Serial Adapter for PLC/Printer/Scanner, Prolific Chipset, Windows/Mac - TAA

Product ID: 1P3FPC-USB-SERIAL



The 1P3FPC-USB-SERIAL 1 Port USB to Serial Adapter lets you add an RS-232 DB9 serial COM port to your laptop or desktop computer, allowing it to control and communicate with a serial peripheral device.


The USB to RS232 cable is a convenient connectivity solution that bridges the gap between current and legacy technologies. The small footprint, data rate of up to 921.6 kbps, COM retention, and 3 ft (0.91 m) cable length makes it the ideal solution for the IT industry, point of sales (POS), industrial applications, AV, and office setups.

This adapter cable allows you to easily add a RS-232 DB9 COM port by connecting it to the commonly found USB Type-A port on your host device. This USB 2.0 converter is compatible with other USB revisions. It supports Windows, macOS, and Linux (including the latest versions) for maximum compatibility.

1P3FPC-USB-SERIAL backed for 2-years by StarTech.com, including free lifetime 24/5 multi-lingual technical assistance.

Certifications, Reports and Compatibility



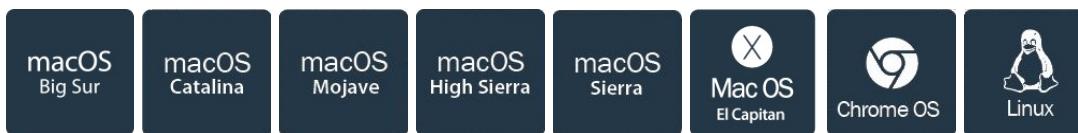

Applications

Features

- **USB TO SERIAL:** Easily connect serial RS232 (DB9) devices to a computer with this USB to serial adapter. Secure the cable using the screw-lock nuts located on the male serial DB9 connector. COM retention between reboots
- **DEVICE COMPATIBILITY:** Use this USB to RS232 serial adapter to reliably connect, configure, and monitor serial devices. Compatible with barcode readers/scanners, networks switches, receipt printers, PLCs, medical devices, oscilloscopes, scales, etc.
- **APPLICATIONS:** This USB to serial cable is ideal for IT applications such as server rooms, industrial control/automation, logistics, POS, AV installations, laboratories, etc. Keep using legacy hardware with modern systems with this USB to RS232 cable
- **USB TO SERIAL ADAPTER SPECS:** 3ft (91cm) Cable Length Max Baud 921.6 Kbps 512 Byte FIFO COM Retention Between Reboots Supports Windows, macOS, and Linux Prolific PL2303 Chipset Odd/Even/Mark/Space/None Parity Modes 5/6/7/8 Data Bits
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this USB to serial port adapter is backed for 2-years, including free lifetime 24/5 multi-lingual technical assistance

Hardware

| | |
|--------------------|---------------------|
| Warranty | 2 Years |
| Ports | 1 |
| Interface | Serial |
| Bus Type | USB 2.0 |
| Port Style | Cable Adapters |
| Industry Standards | USB 1.1/2.0 |
| | RS-232 |
| Chipset ID | Prolific - PL2303GT |

Performance

| | |
|-----------------|------------|
| Serial Protocol | RS-232 |
| Max Baud Rate | 921.6 Kbps |

| | |
|--------------|----------------------------------|
| Data Bits | 5, 6, 7, 8 |
| FIFO | 512 Bytes |
| Flow Control | None, CTS/RTS, DSR/DTR, XON/XOFF |
| Parity | Even, Odd, None, Space, and Mark |
| Stop Bits | 1, 1.5, 2 |

Connector(s)

| | |
|-------------------|--|
| Connector Type(s) | 1 - DB-9 (9 pin, D-Sub) 1 - USB 2.0 Type-A (4 pin, 480Mbps) |
|-------------------|--|

Software

| | |
|------------------|---|
| OS Compatibility | Windows 7, 8.1, 10, 11 Windows Server 2016, 2019, 2022 macOS 10.11 to 10.15, 11.0, 12.0, 13.0, 14.0, 15.0, 26.1 Linux 4.15.x and up - LTS Versions only Chrome OS |
|------------------|---|

Special Notes / Requirements

| | |
|-------------------------------|---|
| System and Cable Requirements | Computer with an available USB Type A port version 1.1 or greater |
|-------------------------------|---|

Environmental

| | |
|-----------------------|------------------------------|
| Operating Temperature | 0C to 80C (32F to 176F) |
| Storage Temperature | -20C to 100C (-4F to 212F) |
| Humidity | 20% to 80% RH Non-Condensing |

Physical Characteristics

| | |
|----------------|-------------------|
| Color | Black |
| Material | Plastic |
| Cable Length | 36.0 in [91.5 cm] |
| Product Length | 36.0 in [91.5 cm] |
| Product Width | 1.8 in [4.5 cm] |

Product Height 0.6 in [1.6 cm]

Weight of Product 1.4 oz [39.2 g]

Packaging Information

Package Quantity 1

Package Length 5.8 in [14.8 cm]

Package Width 4.9 in [12.4 cm]

Package Height 0.9 in [2.3 cm]

Shipping (Package) Weight 1.8 oz [50.0 g]

What's in the Box

Included in Package 1 - USB to Serial Adapter

1 - Quick-start Guide

Warranty Information

Warranty 2 Years

**Product appearance and specifications are subject to change without notice.*