


Cat5e Patch Cable with Snagless RJ45 Connectors - 30 ft, Red

Product ID: 45PATCH30RD

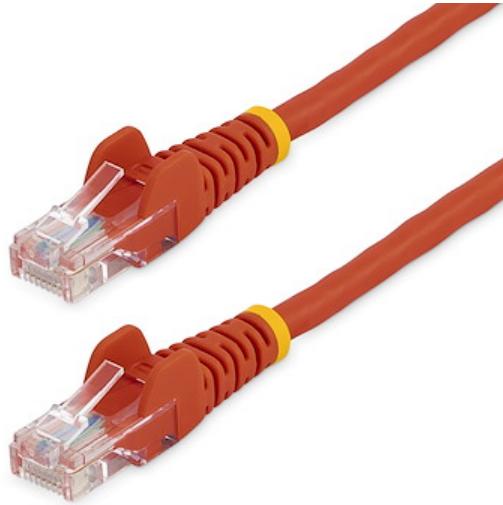

This 30-foot Cat5e cable meets or exceeds all Category 5e cable specifications to ensure reliable Ethernet network connections. Plus, the cable features a durable red PVC jacket that enables you to color code your network cable runs as needed.

For easier cable runs, the snagless connectors protect the cable's RJ45 clips during installation, making them less likely to snag or break. This ensures a sturdy connection by preventing the cable from becoming loose from the port.

The cable features moulded boots that offer connector strain relief, by stopping the RJ45 connector termination points from bending at sharp angles, and reducing the risk of damage to the cable, which could decrease network performance.

Get the highest value for your cable investment with our Cat 5e cables, each one manufactured using high-quality copper conductors.

Ensure high-performance capability for your demanding Ethernet applications, such as Power-over-Ethernet, using cables that include 24 AWG copper.

Rely on our RJ45 connectors to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

The 45PATCH30RD is backed by StarTech.com's lifetime warranty for guaranteed reliability.

Certifications, Reports and Compatibility



Applications

- Designed for use with Fast Ethernet networks
- Connect between computers, hubs, switches, print servers and patch panels
- Connect a workstation to an RJ45 wall outlet
- Extend the reach of your Ethernet network devices by 30 ft

Features

- Prevent cable damage with moulded RJ45 connectors that also offer strain relief
- Create secured connections with snagless clips that protect the connectors during installation
- Guaranteed reliability with a lifetime warranty
- Carefully constructed and tested, to keep Near End Crosstalk (NEXT) well within acceptable limits

Hardware

Warranty	Lifetime
Number of Conductors	4 Pair UTP
Cable Jacket Material	PVC - Polyvinyl Chloride
Fire Rating	CM Rated
Cable Type	Snagless
Wiring Standard	TIA/EIA-568-B.1-2001 T568B

Performance

Cable Rating	CAT5e - 100 MHz
--------------	-----------------

Connector(s)

Connector A	1 - RJ-45
Connector B	1 - RJ-45

Physical Characteristics

Color	Red
Wire Gauge	28 AWG

Conductor Type	Stranded Copper
Cable Length	30.0 ft [9.1 m]
Product Length	30.0 ft [9.1 m]
Product Width	0.5 in [1.2 cm]
Product Height	0.3 in [7.8 mm]
Weight of Product	10.8 oz [306.0 g]

Packaging Information

Package Quantity	1
Package Length	8.2 in [20.8 cm]
Package Width	8.5 in [21.5 cm]
Package Height	1.6 in [4.1 cm]
Shipping (Package) Weight	11.3 oz [320.0 g]

What's in the Box

Included in Package	1 - 30 ft. Cat5e Patch Cable - Red
---------------------	------------------------------------

Warranty Information

Warranty	Lifetime
----------	----------

**Product appearance and specifications are subject to change without notice.*

