


## Cat5e Patch Cable with Snagless RJ45 Connectors - 3 ft, Gray

**Product ID:** 45PATCH3GR

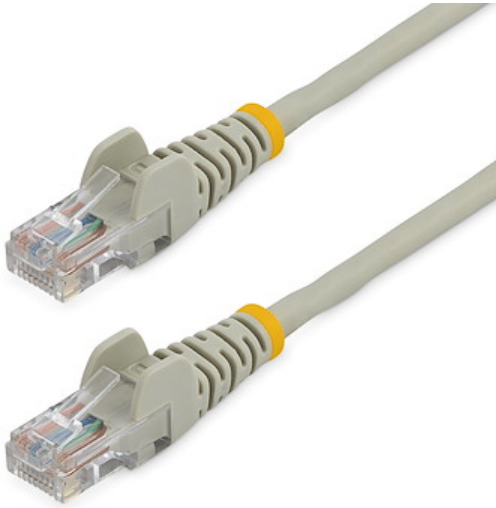

This 3-foot Cat5e cable meets or exceeds all Category 5e cable specifications to ensure reliable Ethernet network connections. Plus, the cable features a durable gray PVC jacket that enables you to color code your network cable runs as needed.

For easier cable runs, the snagless connectors protect the cable's RJ45 clips during installation, making them less likely to snag or break. This ensures a sturdy connection by preventing the cable from becoming loose from the port.

The cable features moulded boots that offer connector strain relief, by stopping the RJ45 connector termination points from bending at sharp angles, and reducing the risk of damage to the cable, which could decrease network performance.

Get the highest value for your cable investment with our Cat 5e cables, each one manufactured using high-quality copper conductors.

Ensure high-performance capability for your demanding Ethernet applications, such as Power-over-Ethernet, using cables that include 24 AWG copper.

Rely on our RJ45 connectors to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

The 45PATCH3GR is backed by StarTech.com's lifetime warranty for guaranteed reliability.

## Certifications, Reports and Compatibility



## Applications

- Designed for use with Fast Ethernet networks
- Connect between computers, hubs, switches, print servers and patch panels
- Connect a workstation to an RJ45 wall outlet

## Features

- Prevent cable damage with moulded RJ45 connectors that also offer strain relief
- Create secured connections with snagless clips that protect the connectors during installation
- Guaranteed reliability with a lifetime warranty
- Carefully constructed and tested, to keep Near End Crosstalk (NEXT) well within acceptable limits

### Hardware

|                       |                          |
|-----------------------|--------------------------|
| Warranty              | Lifetime                 |
| Number of Conductors  | 4 Pair UTP               |
| Cable Jacket Material | PVC - Polyvinyl Chloride |
| Fire Rating           | CM Rated                 |
| Cable Type            | Snagless                 |

### Performance

|              |                 |
|--------------|-----------------|
| Cable Rating | CAT5e - 100 MHz |
|--------------|-----------------|

### Connector(s)

|             |           |
|-------------|-----------|
| Connector A | 1 - RJ-45 |
| Connector B | 1 - RJ-45 |

### Physical Characteristics

|                |                 |
|----------------|-----------------|
| Color          | Gray            |
| Wire Gauge     | 24 AWG          |
| Conductor Type | Stranded Copper |
| Cable Length   | 3.0 ft [0.9 m]  |

|                   |                |
|-------------------|----------------|
| Product Length    | 3.0 ft [0.9 m] |
| Weight of Product | 1.3 oz [37 g]  |

---

#### Packaging Information

|                           |                  |
|---------------------------|------------------|
| Package Quantity          | 1                |
| Package Length            | 7.0 in [17.7 cm] |
| Package Width             | 7.8 in [19.9 cm] |
| Package Height            | 0.8 in [2.1 cm]  |
| Shipping (Package) Weight | 1.7 oz [48.0 g]  |

---

#### What's in the Box

|                     |                                    |
|---------------------|------------------------------------|
| Included in Package | 1 - 3 ft. Cat5e Patch Cable - Gray |
|---------------------|------------------------------------|

---

#### Warranty Information

|          |          |
|----------|----------|
| Warranty | Lifetime |
|----------|----------|

---

***\*Product appearance and specifications are subject to change without notice.***