


## Cat5e Patch Cable with Snagless RJ45 Connectors - 3 ft, Red

Product ID: 45PATCH3RD

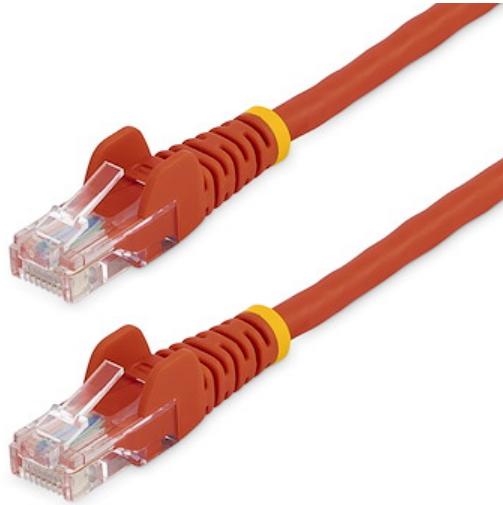

This 3-foot Cat5e cable meets or exceeds all Category 5e cable specifications to ensure reliable Ethernet network connections. Plus, the cable features a durable red PVC jacket that enables you to color code your network cable runs as needed.

For easier cable runs, the snagless connectors protect the cable's RJ45 clips during installation, making them less likely to snag or break. This ensures a sturdy connection by preventing the cable from becoming loose from the port.

The cable features moulded boots that offer connector strain relief, by stopping the RJ45 connector termination points from bending at sharp angles, and reducing the risk of damage to the cable, which could decrease network performance.

Get the highest value for your cable investment with our Cat 5e cables, each one manufactured using high-quality copper conductors.

Ensure high-performance capability for your demanding Ethernet applications, such as Power-over-Ethernet, using cables that include 24 AWG copper.

Rely on our RJ45 connectors to deliver optimum conductivity while eliminating signal loss due to oxidation or corrosion.

The 45PATCH3RD is backed by StarTech.com's lifetime warranty for guaranteed reliability.

## Certifications, Reports and Compatibility



## Applications

- Designed for use with Fast Ethernet networks
- Connect between computers, hubs, switches, print servers and patch panels
- Connect a workstation to an RJ45 wall outlet

## Features

- Prevent cable damage with moulded RJ45 connectors that also offer strain relief
- Create secured connections with snagless clips that protect the connectors during installation
- Guaranteed reliability with a lifetime warranty
- Carefully constructed and tested, to keep Near End Crosstalk (NEXT) well within acceptable limits

---

### Hardware

Warranty	Lifetime
Number of Conductors	4 pair UTP
Cable Jacket Material	PVC - Polyvinyl Chloride
Fire Rating	CM Rated
Cable Type	Snagless

---

### Performance

Cable Rating	CAT5e - 100 MHz
--------------	-----------------

---

### Connector(s)

Connector A	1 - RJ-45
Connector B	1 - RJ-45

---

### Physical Characteristics

Color	Red
Wire Gauge	24 AWG
Conductor Type	Stranded Copper
Cable Length	3.0 ft [0.9 m]

---

Product Length	3.0 ft [0.9 m]
Product Width	0.4 in [1.1 cm]
Product Height	0.6 in [1.4 cm]
Weight of Product	1.4 oz [40.0 g]

---

**Packaging Information**

Package Quantity	1
Package Length	7.1 in [18.0 cm]
Package Width	7.8 in [19.8 cm]
Package Height	0.7 in [1.9 cm]
Shipping (Package) Weight	1.8 oz [50.0 g]

---

**What's in the Box**

Included in Package	1 - 3 ft. Cat5e Patch Cable - Red
---------------------	-----------------------------------

---

**Warranty Information**

Warranty	Lifetime
----------	----------

---

*\*Product appearance and specifications are subject to change without notice.*

