


Desktop Quad Monitor Stand - Ergonomic VESA 4 Monitor Arm (2x2) up to 32" (17.6lb/8kg) - Free Standing Articulating Universal Pole Mount - Height Adjustable/Tilt/Swivel/Rotate - Silver

Product ID: ARMQUADSS

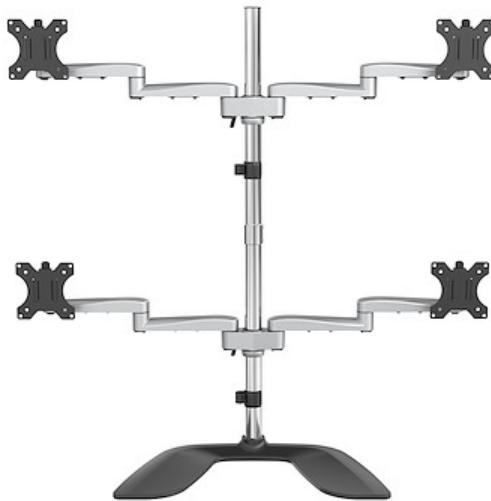

Boost productivity and customize your workspace with this quad-monitor stand, suspending four monitors above your desk. Enjoy optimum viewing with four articulating monitor arms, providing a wide range of motion. The free-standing base gives you flexibility in placing your setup within your workspace.

Constructed of aluminum and steel, the heavy-duty four-monitor stand lets you set up your workspace for optimum productivity. The monitor stand supports four VESA mount (75x75, 100x100) monitors up to 32" each, with a maximum weight capacity of up to 17.6 lb./8 kg per display.

Create a multi-monitor workstation that works best for you. Take advantage of four-screen efficiency for financial analysis, web coding, video editing or many other applications. Customize your setup by adjusting your display height, position and viewing angles for an ergonomic workspace. The swiveling arms provide maximum viewing flexibility.

Place your monitors at the ideal height. Simply adjust the display height along the 35.6 in (904 mm) pole. Align your monitors with the micro-adjustment feature.

The four-screen monitor stand lets you extend the articulating arms up to 16.6" (42.2 cm) to position your monitors in the ideal position. Tilt your monitors +90/-40 degrees and swivel +/-90 degrees. Rotate your displays 360 degrees for portrait or landscape viewing.

Neatly route your cables with the cable-management channels.

ARMQUADSS is backed by a StarTech.com 5-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility



Applications

- Create a more ergonomic workspace in office, commercial or institutional environments
- Utilize four-screen efficiency for financial analysis, web coding, video editing or many other applications
- Enhance productivity and free up space in your home office workstation

Features

- QUAD (2X2) 32 INCH MONITOR STAND: VESA 75x75/100x100mm compatible heavy duty desktop multi monitor mount supports 4 displays up to 32" (17.6lb/8kg) per screen w/ articulation & height adjustment
- WIDE RANGE OF MOTION: Ergonomic articulating monitor stand with +90/-40 tilt, +/- 90 swivel, 360 rotation; Each row of displays has a height adjustable range of 15.7" along 35.6" pole (tools incl)
- STABLE & NON-SLIP: Aluminum free standing monitor mount w/ u-shaped base (11.8" (300mm) x 20.5" (520mm)) for max stability & flexible placement; Anti-slip rubber pads prevent scratches on desk surface
- EASY INSTALLATION: Silver four LCD/LED monitor mount with slide-and-click design makes assembling the monitor arms & VESA adapters easy, reducing set-up time; Align monitors w/ micro height adjustment
- ADJUSTABLE SET UP: Quad monitor stand w/ cable management clips along the arms & center pole to organize cables for a tidy computer workspace & holds incl. adjustment tools for articulation tension

Hardware

Warranty	5 Years
Cable Management	Yes
Articulating	Yes
# of Displays Supported	4
Mounting Options	Desktop Stand
VESA Hole Pattern(s)	75x75 mm
	100x100 mm

Performance

Weight Capacity (Per Display)	17.6 lb [8 kg]
-------------------------------	----------------

Maximum Display Size	32"
Height Adjustment	Yes
Maximum Arm Extension	16.6 in [422 mm]
Display Tilt	+90 / -40
Display Swivel	+90 / - 90
Display Rotation	360

Physical Characteristics

Color	Silver
Product Length	21.8 in [55.3 cm]
Product Width	13.7 in [34.8 cm]
Product Height	4.9 in [12.5 cm]
Weight of Product	15.2 lb [6.9 kg]

Packaging Information

Package Quantity	1
Package Length	21.9 in [55.6 cm]
Package Width	13.8 in [35.0 cm]
Package Height	5.0 in [12.6 cm]
Shipping (Package) Weight	18.7 lb [8.5 kg]

What's in the Box

Included in Package	4 - Swivel Arms
	4 - VESA Mounts
	2 - Shoulders
	1 - Upper Pole
	1 - Lower Pole

- 1 - Pole Connector
- 1 - Base
- 2 - Cable-Management Clips
- 16 - M4x16 Screws
- 16 - M4x12 Screws
- 16 - M5x16 Screws
- 16 - M5x12 Screws
- 16 - M4x20 Screws
- 16 - M5x20 Screws
- 32 - Spacers
- 16 - Washers
- 1 - 3mm Hex Key
- 1 - 6mm Hex Key
- 1 - User Manual

**Warranty
Information**

Warranty	5 Years
----------	---------

**Product appearance and specifications are subject to change without notice.*