

USB C Multiport Converter - USB-C to HDMI 2.0b 4K 60Hz (HDR10), 100W Power Delivery Pass-Through, 4-Port USB 3.0 Hub - USB Type-C Mini Dock - 12" (30cm) Long Attached Cable

**Product ID:** DKT30CHPD3



This USB-C multiport adapter with DP 1.4 supports 4K 60Hz HDMI and turns your MacBook Pro, Dell XPS, or other USB-C laptops or tablet into a workstation, anywhere you go. The USB Type-C multiport adapter provides 4K HDMI video output, three USB 3.2 Gen 1 Type-A (5Gbps) ports including one BC 1.2 charge port; one USB-C port supporting both the 100W PD passthrough, all through one connection to your laptop's USB-C or Thunderbolt 3 port. Plus, it offers advanced charging through USB Power Delivery 3.0 and an extra-long attached 12-inch (30 cm) host cable for an extended reach to offer more set up flexibility.

The portable docking station connects your laptop to a 4K 60Hz HDMI monitor (4096 x 2160p) to create a powerful workstation. It can also connect to an ultrawide monitor.

The USB-C to USB 3.1 Gen 1 hub gives you three USB-A ports to connect your legacy USB devices, plus one shared USB-C port for either power delivery pass through.


With support for USB PD 3.0 (up to 100W), the USB Type-C multiport adapter lets you power and charge your laptop, and power your peripherals when connected to a USB-C power adapter. PD 3.0 features Fast Role Swap to prevent USB data disruption when you switch power sources (USB-C power adapter to bus power).

The DKT30CHPD3 is backed by a StarTech.com 3-year warranty and free lifetime technical support.

Note: To ensure full adapter functionality, your laptop's USB-C port must support USB Power Delivery.

## Certifications, Reports and Compatibility



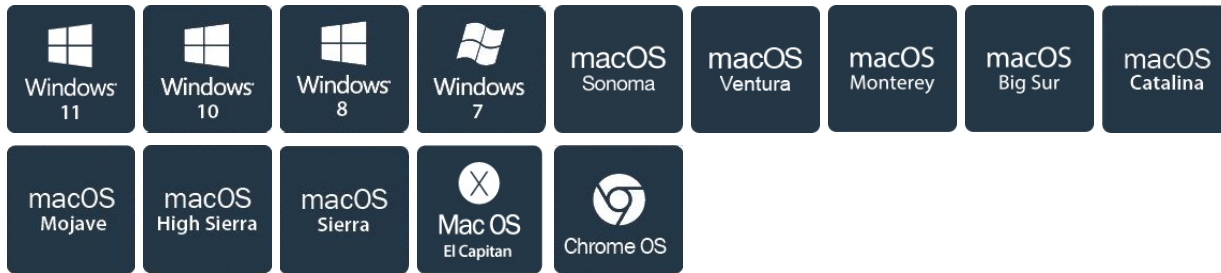

## Applications

## Features

- **5-IN-1 MULTIPOINT ADAPTER:** USB-C multiport adapter with DP 1.4 Alt-Mode up to 4K 60Hz (4K 30Hz with DP 1.2) HDMI 2.0b (HDR10) video; 4-Port USB Hub 5Gbps: 3x USB-A (USB 3.2/3.1 Gen 1) with 1x BC 1.2 charging, 1x USB-C (100W PD Passthrough)
- **EXTRA LONG CABLE:** USB C to HDMI multiport adapter with 12" (30cm) attached cable for extended reach to reduce port/connector strain on 2-in-1 devices like Surface Pro 7, iPad Pro, HP Elite x2 & laptops on riser stands
- **PORTABLE & COMPACT:** Portable all-in-one USB Type-C multiport adapter is made from durable aluminum & designed for easy transport in a laptop bag for convenient on-the-go use between office, home office, shared office spaces, and business travel
- **RELIABLE PERFORMANCE:** USB bus powered or via external USB-C power adapter; 100W Power Delivery 3.0 pass through w/ 12W reserved for adapter to avoid video flickering, device dropouts or overdrawing power common in other hubs; up to 88W for laptop charging
- **WIDE COMPATIBILITY:** Compatible with USB-C laptops, ultrabooks & Chromebooks, plus Thunderbolt 3 laptops from HP, Dell, Lenovo, MacBooks (Intel processor & M1 chip), and Surface Laptop 4; USBC mini dock works w/ Windows, macOS, iPadOS, Android & Chrome OS
- **4K 60HZ WITH DP 1.4 ALT-MODE:** Supports 4K 60Hz on host devices that support DP 1.4 Alt-Mode (min. Intel 11th Gen); on host devices that support DP 1.2 Alt-Mode, maximum video output resolution is 4K 30Hz; works w/ ultra-wide monitors up to 3440x1440@60Hz

---

### Hardware

Warranty	3 Years
4K Support	Yes
Fast-Charge Port(s)	No
Displays Supported	1
Interface	USB 3.2 Gen 1
Bus Type	USB-C

Industry Standards	USB 3.0 - Backward compatible with USB 2.0 and 1.1
Chipset ID	Parade Technologies - PS176 VIA Tech - VL102 VIA Tech - VL817

---

#### Performance

Maximum Data Transfer Rate	5 Gbps (USB 3.1) Gen 1
Maximum Digital Resolutions	4K @ 60Hz (on hosts that support DP 1.4), 4K @ 30Hz (on hosts that support DP 1.2)
Type and Rate	USB 3.0 - 5 Gbit/s
UASP Support	Yes

---

#### Connector(s)

Connector Type(s)	1 - HDMI (19 pin) 3 - USB Type-A (9 pin, 5 Gbps) 1 - USB Type-C (24 pin) USB Power Delivery Only
Host Connectors	1 - USB 3.2 Type-C (24 pin, Gen 1, 5Gbps)

---

#### Software

OS Compatibility	Windows 7, 8, 8.1, 10, 11, 11 ARM macOS 10.9 to 10.15, 11.0, 12.0, 13.0, 14.0, 15.0, 26.1 Chrome OS
------------------	---

---

#### Power

Power Source	Bus Powered and Host USB-C Power Adapter
Power Delivery	100W
Output Voltage	5 DC

---

#### Environmental

Operating Temperature	0 to +45
Storage Temperature	-10 to +70
Humidity	10% to 90 % RH

---

#### Physical Characteristics

Color	Black & Gray
Material	Plastic
Cable Length	11.8 in [30 cm]
Product Length	1.3 in [3.4 cm]
Product Width	5.9 in [15.0 cm]
Product Height	0.4 in [1.1 cm]
Weight of Product	2.2 oz [61.0 g]

---

**Packaging Information**

Package Quantity	1
Package Length	5.6 in [14.3 cm]
Package Width	6.8 in [17.2 cm]
Package Height	1.3 in [3.4 cm]
Shipping (Package) Weight	4.2 oz [118.0 g]

---

**What's in the Box**

Included in Package	1 - USB-C Multiport Adapter
	1 - Product Documentation

---

**Warranty Information**

Warranty	3 Years
----------	---------

---

*\*Product appearance and specifications are subject to change without notice.*