

USB C Multiport Adapter - USB-C to 4K HDMI, 100W Power Delivery Pass-through, SD/MicroSD Slot, 3-Port USB 3.0 Hub - USB Type-C Mini Dock - 12" (30cm) Long Attached Cable

Product ID: DKT30CHSDPD



This USB-C multiport adapter with HDMI turns your MacBook Pro, Dell XPS, or other USB-C laptops into a workstation, anywhere you go. The USB Type-C multiport adapter provides 4K HDMI video output, two USB 3.2 Gen 2 Type-A (10Gbps) ports, and a USB Type-C port (power/data), all through one connection to your laptop's USB-C or Thunderbolt 3 port. Plus, it offers advanced charging through USB Power Delivery 3.0 and an extra-long attached 12-inch (30 cm) host cable for an extended reach to offer more set up flexibility.

The portable docking station connects your laptop to a 4K 30Hz HDMI monitor (3840 x 2160p) to create a powerful workstation. It can also connect to an ultrawide monitor.

The USB-C to USB 3.2 Gen 1 hub gives you two USB-A ports one and a USB-C port (shared power/data) to connect your latest and legacy USB devices.


Access your multimedia content with ease. The multiport adapter provides direct access to your SD, SDHC and SDXC memory cards or microSD (uSD) cards.

With support for USB PD 3.0 (up to 100W), the USB Type-C multiport adapter lets you power and charge your laptop, and power your peripherals when connected to a USB-C power adapter. PD 3.0 features Fast Role Swap to prevent USB data disruption when you switch power sources (USB-C power adapter to bus power).

The DKT30CHSDPD is backed by a StarTech.com 3-year warranty and free lifetime technical support.

Note: To ensure full adapter functionality, your laptop's USB-C port must support USB Power Delivery.

Certifications, Reports and Compatibility

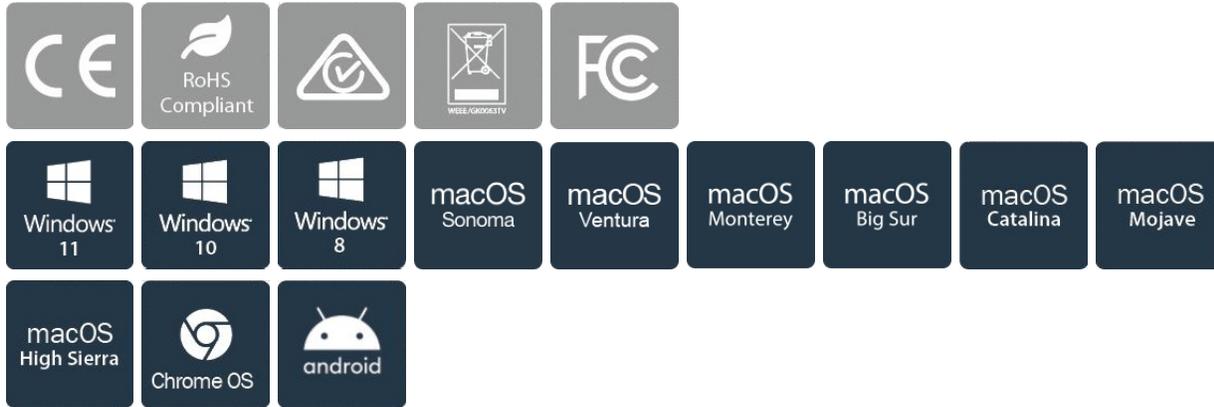

Applications

Features

- **6-IN-1 MULTIPOINT ADAPTER:** USB-C multiport adapter w/ HDMI 4K 30Hz video output, 2x USB-A (USB 3.1 Gen 1 5Gbps & BC 1.2 charging), 1x USB-C (Data + 100W Power Delivery 3.0), MicroSD & SD Card Reader; works w/ ultra-wide monitors up to 3440x1440 @30Hz
- **EXTRA LONG CABLE:** USB C mini dock with 12" (30cm) attached cable for extended reach to reduce port/connector strain on 2-in-1 devices like Surface Pro 7, iPad Pro, HP Elite x2 & laptops on riser stands
- **RELIABLE PERFORMANCE:** USB bus powered or via external USB-C power adapter; 100W Power Delivery 3.0 pass through w/ 12W reserved for adapter to avoid video flickering, device dropouts or overdrawing power common in other hubs; up to 88W for laptop charging
- **WIDE COMPATIBILITY:** Fully compatible with USB-C laptops, ultrabooks & Chromebooks, plus Thunderbolt 3 laptops from HP, Dell, Lenovo, MacBooks (Intel processor and M1 chip), and Surface; works w/ Windows, macOS, iPadOS, Android and Chrome OS
- **PORTABLE & COMPACT:** Portable USB Type-C multiport adapter is designed for easy transport in a laptop bag for convenient on-the-go use between office, home office, shared office spaces, and business travel

Hardware

Warranty	3 Years
4K Support	Yes
Fast-Charge Port(s)	Yes
Displays Supported	1
Ports	6
Interface	USB 3.2 Gen 1

Bus Type	USB-C
USB Pass-Through	Yes
Chipset ID	Fresco Logic - FL7102 Parade - PS176 Fresco Logic - FL5001 ALCORMICR - AU84612

Performance

Maximum Data Transfer Rate	5Gbps
Maximum Digital Resolutions	4K 30Hz
Type and Rate	USB 3.2 Gen 1 - 5 Gbit/s
Memory Media Type	SD/MMC (Secure Digital/Multimedia Card) microSD (Micro Secure Digital)

Connector(s)

External Ports	1 - HDMI 1 - USB 3.2 Type-C (24 pin, Gen 1, 5Gbps) 1 - USB 3.2 Type-A (9 pin, Gen 1, 5Gbps) 1 - USB 3.2 Type-A (9 pin, Fast-Charge) 1 - SD / MMC Slot 1 - MicroSD
Host Connectors	1 - USB 3.2 Type-C (24 pin, Gen 1, 5Gbps)

Software

OS Compatibility	macOS High Sierra (10.13), macOS Mojave (10.14), macOS Catalina (10.15), macOS Big Sur (11.0) macOS Monterey (12.0) macOS Ventura (13.0) macOS Sonoma (14.0) macOS Tahoe (26.1)
------------------	---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

Windows 8, Windows 10, Windows 11, Windows 11 ARM,
Chrome OS, iPadOS, Android,

Special Notes / Requirements

System and Cable Requirements	Host laptop with an available USB-C port (to ensure full functionality, the laptop's USB-C port must support DP alt mode).
-------------------------------	----------------------------------------------------------------------------------------------------------------------------

Power

Power Source	Bus Powered and Host USB-C Power Adapter
Power Delivery	100W
Output Voltage	5 DC
Power Consumption (In Watts)	12W

Environmental

Operating Temperature	0 to +70
Storage Temperature	-10 to +55
Humidity	5% to 90 % RH (no condensation)

Physical Characteristics

Color	Space Gray
Cable Length	11.8 in [30 cm]
Product Length	3.7 in [9.5 cm]
Product Width	1.8 in [4.5 cm]
Product Height	0.5 in [1.2 cm]
Weight of Product	2.5 oz [70.0 g]

Packaging Information

Package Quantity	1
Package Length	6.8 in [17.2 cm]
Package Width	5.6 in [14.3 cm]
Package Height	1.3 in [3.4 cm]

Shipping (Package) Weight	4.2 oz [118.0 g]
------------------------------	------------------

What's in the Box

Included in Package	1 - USB Type-C Multiport Adapter
	1 - Product Documentation

**Warranty
Information**

Warranty	3 Years
----------	---------

****Product appearance and specifications are subject to change without notice.***