


2m Fiber Optic Cable - Multimode Duplex 62.5/125 LSZH Fiber Jumper Cord - LC/ST

Product ID: FIBLCST2

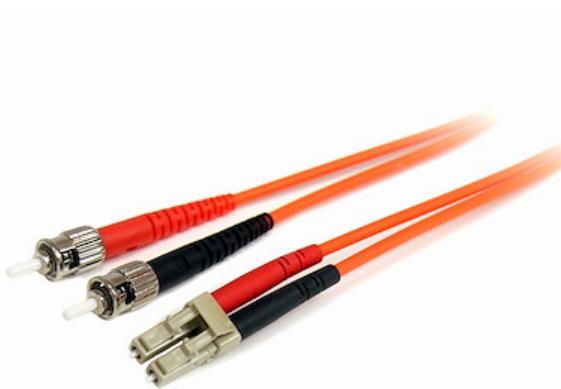

The FIBLCST2, 2-meter (6.6ft) Multimode 62.5/125 Duplex Fiber Patch Cable is terminated with one LC (male) connector and one ST (male) connector, to provide the necessary connection between fiber networking devices for high-speed, long distance networks.

This LC-ST patch cable is housed in a LSZH (Low-Smoke, Zero-Halogen) flame retardant jacket, to ensure minimal smoke, toxicity and corrosion when exposed to high sources of heat, in the event of a fire. Making it ideal for use in industrial settings, central offices and schools, as well as residential settings where building codes are a consideration.

To ensure optimum performance, our multimode fiber duplex cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Backed by Lifetime Warranty, our LC-ST Multimode Fiber Patch cable is guaranteed to provide long-lasting dependability, and top quality performance.

Certifications, Reports and Compatibility



Applications

- Ideal solution for data applications requiring high speed data transmission
- Broadband systems
- Telecommunication/Data communication

- Used by long distance networks with mission critical data

Features

- Attenuation loss meets or exceeds industry standards
- LSZH (Low-Smoke, Zero-Halogen) cable jacket
- Immune to electrical interference

Hardware

| | |
|----------------------|-------------------------------------|
| Warranty | Lifetime |
| Fiber Size | 62.5/125 |
| Fire Rating | LSZH Rated (Low Smoke Zero Halogen) |
| Fiber Classification | OM1 |

Performance

| | |
|----------------------------|----------------|
| Maximum Data Transfer Rate | 10Gbps |
| Cable Rating | 1Gbps / 10Gbps |
| Type | Multi Mode |

Connector(s)

| | |
|-------------|---------------------------|
| Connector A | 1 - Fiber Optic LC Duplex |
| Connector B | 1 - Fiber Optic ST Duplex |

Environmental

| | |
|-----------------------|---------------------------|
| Operating Temperature | -20C to 60C (-4F to 140F) |
| Storage Temperature | -20C to 60C (-4F to 140F) |
| Humidity | 0~90% RH |

Physical Characteristics

| | |
|----------------|--------------|
| Color | Orange |
| Cable Length | 6.6 ft [2 m] |
| Product Length | 6.6 ft [2 m] |

| | |
|-------------------|---------------|
| Weight of Product | 1.4 oz [40 g] |
|-------------------|---------------|

Packaging Information

| | |
|---------------------------|------------------|
| Package Quantity | 1 |
| Package Length | 5.9 in [15.0 cm] |
| Package Width | 7.8 in [19.9 cm] |
| Package Height | 0.8 in [2.1 cm] |
| Shipping (Package) Weight | 1.7 oz [48.0 g] |

What's in the Box

| | |
|---------------------|------------------------------------------------------------|
| Included in Package | 1 - 2m Multimode 62.5/125 Duplex Fiber Patch Cable LC – ST |
|---------------------|------------------------------------------------------------|

Warranty Information

| | |
|----------|----------|
| Warranty | Lifetime |
|----------|----------|

**Product appearance and specifications are subject to change without notice.*