


2m (6.6ft) SC to SC OM1 Multimode Fiber Optic Cable, 62.5/125 Fiber Size, 10G Networks - LSZH Fiber Patch Cord

**Product ID:** FIBSCSC2

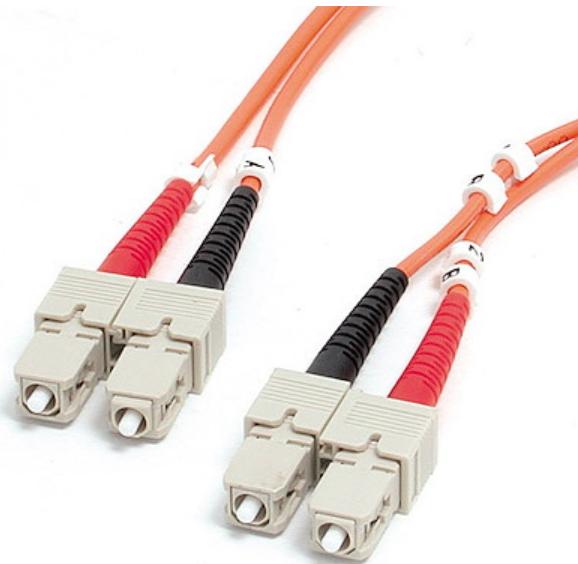

The FIBSCSC2 2-meter (6.6ft) Multimode 62.5/125 Duplex Fiber Patch Cable is terminated at both ends with SC (male) connectors, to provide the necessary connection between fiber networking devices for high-speed, long distance networks.

This SC-SC patch cable is housed in a LSZH (Low-Smoke, Zero-Halogen) flame retardant jacket, to ensure minimal smoke, toxicity and corrosion when exposed to high sources of heat, in the event of a fire. Making it ideal for use in industrial settings, central offices and schools, as well as residential settings where building codes are a consideration.

To ensure optimum performance, our multimode fiber duplex cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Backed by Lifetime Warranty, our SC-SC Multimode Fiber Patch cable is guaranteed to provide long-lasting dependability, and top quality performance.

## Certifications, Reports and Compatibility



## Applications

- Used by long distance networks with mission critical data
- Telecommunication/Data communication

- Broadband systems
- Ideal solution for data applications requiring high speed data transmission

## Features

- **FIBER CABLE:** OM1 Fiber Cable is immune to EMI and supports up to 10 Gbps Ethernet; Duplex-cord with color-coded TX/RX connectors enable quick visual identification of polarity
- **QUALITY CONSTRUCTION:** SC/SC connectors with UPC ends significantly improve return loss; Robust molded connector strain reliefs minimize wear from bending
- **SAFETY AND RELIABILITY:** Individually tested for signal integrity; LSZH (Low-Smoke, Zero-Halogen) cable jacket emits low-smoke and toxic fumes if combusted
- **SPECS:** Cable length: 2m (6.6ft); Color: Orange; Connectors: SC/SC; Fiber Size: 62.5/125m; Fiber Classification: OM1; Fiber Type: Multi Mode; Supported network speed: 1/10 Gbps; Cable OD: 2.9mm
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this fiber optic cable is backed for life, including free lifetime 24/5 multi-lingual technical assistance

---

### Hardware

Warranty	Lifetime
Fiber Size	62.5/125
Fire Rating	LSZH Rated (Low Smoke Zero Halogen)
Fiber Classification	OM1

---

### Performance

Maximum Data Transfer Rate	10Gbps
Cable Rating	1Gbps / 10Gbps
Type	Multi Mode

---

### Connector(s)

Connector A	1 - Fiber Optic SC Duplex
Connector B	1 - Fiber Optic SC Duplex

---

### Environmental

Operating Temperature	-20C to 60C (-4F to 140F)
Storage Temperature	-20C to 60C (-4F to 140F)

Humidity 0~90% RH

---

**Physical Characteristics**

Color	Orange
Cable Length	6.6 ft [2 m]
Product Length	6.6 ft [2.0 m]
Product Width	1.0 in [2.5 cm]
Product Height	0.4 in [1.0 cm]
Weight of Product	1.6 oz [45.0 g]

---

**Packaging Information**

Package Quantity	1
Package Length	6.7 in [16.9 cm]
Package Width	6.7 in [16.9 cm]
Package Height	1.4 in [3.5 cm]
Shipping (Package) Weight	1.6 oz [44.0 g]

---

**What's in the Box**

Included in Package	1 - 2 M Multimode Fiber Optic Cable SC-SC
---------------------	---

---

**Warranty Information**

Warranty	Lifetime
----------	----------

---

*\*Product appearance and specifications are subject to change without notice.*