

## 3 Port 2b 1a 1394 Mini PCI Express FireWire Card Adapter - TAA

Product ID: MPEX1394B3




The MPEX1394B3 3-Port Mini PCIe FireWire Card is a PCIe to FireWire-800/FireWire-400 adapter that enables you to add external FireWire connectivity on very small form factor or embedded systems. The PCIe FireWire card provides two FireWire-800 ports and one FireWire-400 port, this adapter card supports the latest external FireWire storage devices at data transfer speeds of up to 800 Mbps.

Using the Mini PCIe (Mini Card) form factor, this adapter card is designed for use in the latest very small form factor computer systems, such as Mini-ITX or custom embedded solutions where a full-sized PCIe card would not fit.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

### Certifications, Reports and Compatibility

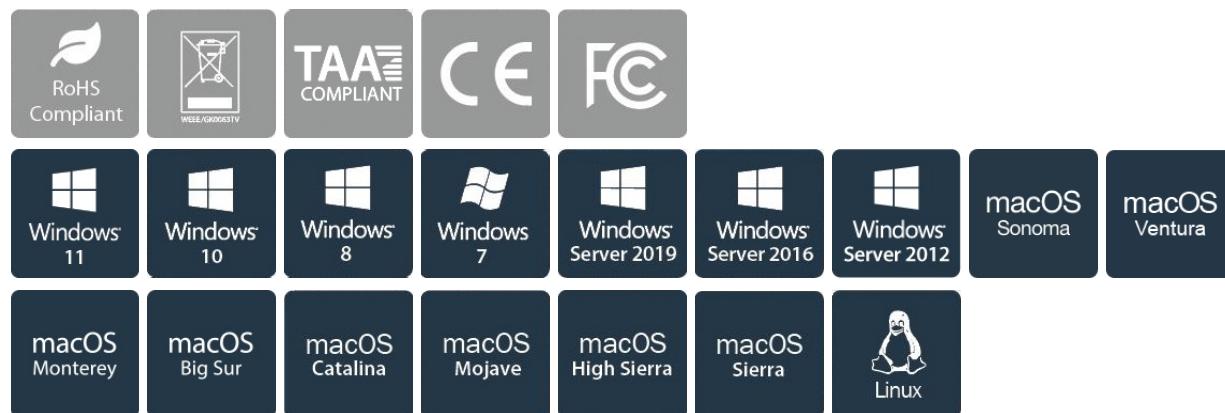

### Applications

- System builders creating a small form factor HTPC with external FireWire storage or A/V equipment
- Custom embedded systems with no room for full or even low profile PCI Express cards

## Features

- 2 external 9-pin FireWire-800 ports with support for data transfer rates up to 800 Mbps
- 1 external 6-pin FireWire-400 port with supported transfer rates up to 400 Mbps
- Compliant with PCI Express Mini Card specification 1.2
- Optional external power support for high-powered FireWire devices
- Compliant with IEEE 1394b and backward compatible with IEEE 1394a - 2000 as well as 1394-1995 standards
- Plug-and-Play and hot-swap compatible

---

### Hardware

Warranty	2 Years
Ports	3
Interface	FireWire 800 (1394b)
	FireWire 400 (1394a)
Bus Type	mini PCI Express
Card Type	Low Profile
Industry Standards	IEEE-1394/1394A/1394B
	OHCI
	PCI Express 1.1
Chipset ID	Texas Instruments - XIO2213B

---

### Performance

Type and Rate	FireWire 800 IEEE-1394b - 800 Mbit/s
	FireWire 400 IEEE-1394a - 400 Mbit/s
MTBF	172,480 hours

---

### Connector(s)

Connector Type(s)	1 - Mini PCI Express x1 (52 pin)
-------------------	----------------------------------

Internal Ports	1 - LP4 (4 pin; Large Drive Power)
External Ports	1 - FireWire 400 (6 pin, IEEE 1394a)
	2 - FireWire 800 (9 pin, IEEE 1394b)

---

**Software**

OS Compatibility	Windows 2000, XP, Vista, 7, 8, 8.1, 10, 11  Windows Server 2003, 2008 R2, 2012, 2016, 2019  macOS 10.6 to 10.15, 11.0, 12.0, 13.0, 14.0, 15.0, 26.1  Linux 3.5.x and up - LTS Versions only
------------------	---

---

**Special Notes / Requirements**

System and Cable Requirements	Available Mini PCI Express expansion slot (full length)
Note	Ensure computer case has an available expansion card slot

---

**Environmental**

Operating Temperature	0C to 70C (32F to 158F)
Storage Temperature	-54C to 150C (-65F to 302F)

---

**Physical Characteristics**

Color	Green
Material	Steel
Product Length	2.0 in [50.0 mm]
Product Width	1.2 in [3.0 cm]
Product Height	0.2 in [0.4 cm]
Weight of Product	3.2 oz [91.0 g]

---

**Packaging Information**

Package Quantity	1
Package Length	6.7 in [17.0 cm]
Package Width	5.7 in [14.4 cm]
Package Height	1.2 in [3.0 cm]

Shipping (Package)  
Weight 6.6 oz [187.0 g]

---

**What's in the Box**

Included in Package	1 - Mini PCI Express FireWire card
	1 - Internal Data Cable
	1 - 4-pin LP4 Molex Adapter Cable
	1 - Full Profile Bracket
	1 - Video Editing Software CD
	1 - Instruction Manual

---

**Warranty  
Information**

Warranty	2 Years
----------	---------

---

*\*Product appearance and specifications are subject to change without notice.*

