


MSA Uncoded Compatible 1m 40G QSFP+ to 4x SFP+ Direct Attach Breakout Cable Twinax - 40GbE QSFP+ to 4x SFP+ Copper DAC 40 Gbps Low Power Passive Transceiver Module DAC

**Product ID:** QSFP4SFPPC1M

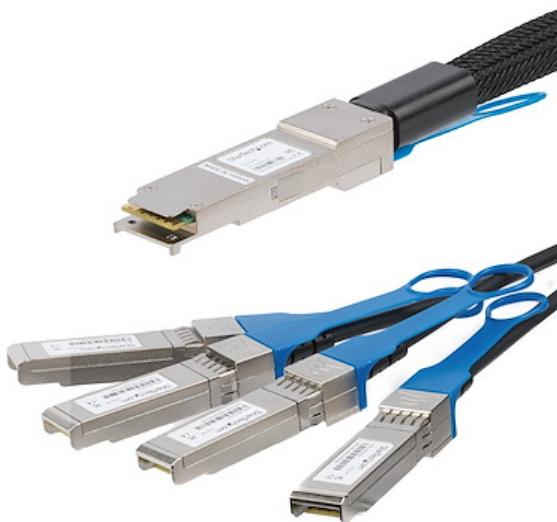

The QSFP4SFPPC1M is an MSA Compliant QSFP+ direct-attach Twinax breakout cable. It is designed, programmed and tested to bridge 40G network equipment with 10G compatible servers or routers. This passive Twin axial cable connects a single QSFP+ port to four 10G SFP+ ports and is fully hot-pluggable making upgrades and replacements seamless by minimizing network disruptions.

At 1 meters long and designed for short-length, high-speed interconnects, this low-power, low-latency copper QSFP+ cable also uses a cost-effective cabling alternative to fiber-optic assemblies. It supports short-distance applications such as point-to-point in-rack and across-rack network switch or server connections, for up to four 10G SFP+ devices.

All StarTech.com QSFP & QSFP+ cables are backed by a lifetime warranty and free lifetime multilingual technical support. StarTech.com offers a wide variety of direct-attach SFP Cables and SFP modules, providing the convenience and reliability you need to ensure dependable network performance.

## Certifications, Reports and Compatibility



## Applications

- Use in 40Gb/10Gb mixed Ethernet network applications
- Point-to-point in-rack server or network switch connections, for up to four devices

## Features

- MSA UNCODED QSFP+ CABLE (DAC): 40Gb direct attach cable works with MSA compliant switches that accept uncoded transceivers and modules
- TECHNICAL SPECS: 1m (3.3ft) 40 Gbps Passive Twinax (Copper) 1x QSFP+ to 4x SFP+ Pluggable Connector 100 Ohm Impedance 30 AWG Wire Gauge PVC Cable Jacket Hot swappable MSA Compliant
- DESIGNED FOR SERVER ROOMS: This DAC is a cost-effective copper alternative to fiber cable inside & between racks; factory termination means high performance & reliability with less maintenance.
- OUTSTANDING SUPPORT: Backed by StarTech.com for the life of the cable itself, not your equipment; our cables won't void your OEM support and with access to our Tech Advisors 5/24.
- WORKS WITH MSA COMPLIANT SWITCHES: Low power 40GbE DAC also works with switch models from Ubiquiti, D-Link, Netgear, Supermicro, TP-Link and more that accept uncoded modules and transceivers

---

### Hardware

Warranty	Lifetime
Compatible Brand	MSA Compliant
Cable Jacket Material	PVC - Polyvinyl Chloride

---

### Performance

Maximum Data Transfer Rate	40Gbps for QSFP+ / 10Gbps for SFP+
Impedance	100 Ohm
Compatible Networks	40 Gbps
Power Consumption (In Watts)	< 0.1 W (per end)

---

### Connector(s)

Connector A	1 - QSFP+
Connector B	4 - SFP+

---

### Environmental

Operating Temperature	0C to 70C (32F to 158F)
Storage Temperature	-40C to 80C (-40F to 158F)

---

### Physical Characteristics

Color	Black
-------	-------

---

Product Length	3.3 ft [1.0 m]
Product Width	0.6 in [1.4 cm]
Product Height	0.5 in [1.2 cm]
Weight of Product	8.4 oz [238.0 g]

---

**Packaging Information**

Package Length	8.4 in [21.3 cm]
Package Width	9.8 in [25.0 cm]
Package Height	1.4 in [3.5 cm]
Shipping (Package) Weight	9.3 oz [264.0 g]

---

**What's in the Box**

Included in Package	1 - QSFP+ to 4x SFP+ cable
---------------------	----------------------------

---

**Warranty Information**

Warranty	Lifetime
----------	----------

---

*\*Product appearance and specifications are subject to change without notice.*

