


2-Post 8U Heavy-Duty Wall-Mount Network Rack, 19" Open Frame Server Rack, 12" Deep, Wall Mount Data Rack for IT / AV / Patch Panel / Computer Equipment

Product ID: RK812WALLO

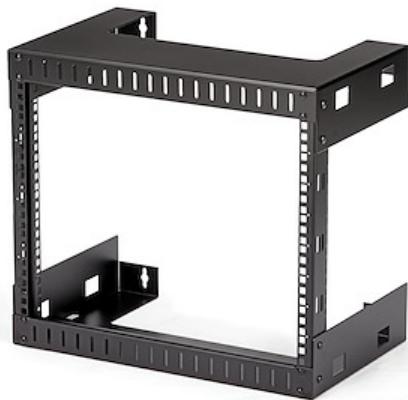

The RK812WALLO 8U Open Frame Wall Mount Equipment Rack (12in Depth) is a high quality, low cost relay rack that is easy to assemble and install into any environment. The rack can be wallmounted or installed as a free standing storage solution.

Able to accommodate common networking, audio-video and telecom equipment, the open rack offers a depth of 12in; the wall mounts are positioned 16in apart (center to center), making it suitable for mounting on virtually any wall surface, based on North American wall frame stud spacing standards.

This 8U rack can be mounted to the wall in a server room, office, or above a doorway, expanding your workspace and keeping your equipment easily accessible.

Certifications, Reports and Compatibility



Applications

- Perfect for installing network switches out of the way and high up on a wall in a branch office, warehouse, or superstore location
- Ideal for small and medium businesses requiring small rack solutions dispersed throughout the organization
- Mounting Audio Video broadcast or distribution components

Features

- **2-POST 8U WALL MOUNT NETWORK RACK:** EIA/ECA-310 compliant open frame server rack with 11.9" (30.3cm) mounting depth is ideal for installing IT / AV / Data equipment, patch panels, switches and shelves in small spaces
- **HEAVY DUTY:** This heavy duty 2 post open frame rack supports unobstructed airflow and is easy to install with a durable design made from SPCC cold-rolled steel with support for up to 176lbs (80Kg) of equipment
- **EFFICIENT FLAT PACK SHIPPING:** The IT rack ships flat packed with ISTA-6 certified packaging (assembly required) to ensure hassle-free installations with complete & undamaged delivery; Comprehensive assembly instructions included
- **HARDWARE INCLUDED:** The 2 post open frame wall mount server rack includes a complete set of M5 square cage nuts, M5 screws and washers to securely mount all of your equipment in the rack
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this 8U open frame wall mount rack is backed for 5 years, including free lifetime 24/5 multi-lingual technical assistance

Hardware

Warranty	Lifetime
Wallmountable	Yes
Rack Type	2-Post
Frame Type	Open Frame
U Height	8U
Special Features	Easy Assembly Wall-Mountable
Mounting Rail Profile	G-Shape
Mounting Hole Types	Square (For Cage Nut)
Industry Standards	EIA/ECA-310-E

Performance

Weight Capacity	176.4 lb [80 kg]
-----------------	------------------

Physical Characteristics

Color	Black
Construction Material	Steel

Product

Measurements

Product Length	19.7 in [50 cm]
Product Width	12.0 in [30.5 cm]
Product Height	18.1 in [45.9 cm]
Weight of Product	16.9 lb [7.6 kg]
Maximum Mounting Depth	11.9 in [30.3 cm]

Packaging Information

Flat Pack (Assembly Required)	Yes
Package Length	22.2 in [56.5 cm]
Package Width	25.6 in [65.0 cm]
Package Height	4.4 in [11.3 cm]
Shipping (Package) Weight	18.1 lb [8.2 kg]

What's in the Box

Included in Package	1 - 8U Rack
	4 - M8x50mm Screws
	32 - M5 Screws
	32 - M5 Cage Nuts
	16 - Assembly Screws
	1 - Installation Guide

Warranty Information

Warranty	Lifetime
----------	----------

****Product appearance and specifications are subject to change without notice.***