

## 3.5" SATA Hard Drive Enclosure - eSATA / USB 3.0 - Trayless

**Product ID:** S351BMU33ET



This eSATA enclosure for 3.5 in. SATA HDDs is perfect for those who require quick and easy access to important data and files. It is ideal if you need easy access to your data or need to back up, archive, or recover data and multimedia content.

### Multiple connectivity options

The external hard drive enclosure supports USB 3.0, also known as USB 3.2 Gen 1, and eSATA, allowing you to access your data through your preferred interface. For fast performance and efficient data transfers, when connected through eSATA, the enclosure supports full SATA III transfer speeds - up to 6Gbps.

For universal compatibility, the enclosure can be connected through USB 3.0 with transfer speeds up 5Gbps, plus support for UASP. The HDD enclosure lets you connect a SATA III (6Gbps) hard drive, but is also compatible with SATA I and II.


### Ease of use

The hard drive enclosure allows you to swap drives in and out as needed with the trayless design. The enclosure is simple to set up and easy to use, with its plug-and-play functionality. It's also equipped with an LED light to indicate power and activity.

### Compact design works great with your Mac or PC

With a sleek, compact style, this hard drive enclosure is a perfect desktop companion for your Mac or PC. It occupies minimal space, and features a fanless design that keeps the enclosure quiet so you can focus on what's important.

## Certifications, Reports and Compatibility

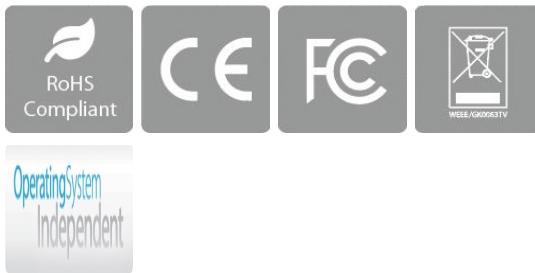

## Applications

- Retrieve data from an old SATA drive, or turn the unused drive into additional external storage space
- Hot-swap drives using a single enclosure instead of having to swap separate enclosures
- Upgrade from a USB 2.0 drive enclosure to faster USB 3.0
- Share large files between computers quickly and securely without a network connection
- Perfect for creative professionals, office, government, and medical personnel, sales executives, teachers, and research scientists who require access to important data and files

## Features

- **VERSATILE FUNCTIONALITY:** This eSATA enclosure for 3.5 in. SATA HDDs is perfect if you need quick and easy access to your data or need to back up, archive, or recover data and multimedia content
- **MAXIMUM COMPATIBILITY:** The universal 3.5" SATA hard drive enclosure can be connected through USB 3.0 with transfer speeds up 5Gbps; The HDD enclosure is also compatible with SATA I and II
- **EASY TO USE:** The external hard drive enclosure allows you to swap drives in and out as needed with the trayless design; The enclosure has plug-and-play functionality
- **SAVES SPACE:** With a sleek, compact style, this trayless hard drive enclosure, occupies minimal space, and features a fanless design that keeps the enclosure quiet so you to focus on what's important
- **THE IT PRO'S CHOICE:** Designed and built for IT professionals, this eSATA / USB 5Gbps enclosure is backed for 2 years, including free lifetime 24/5 multi-lingual technical assistance

---

### Hardware

Warranty	2 Years
Fan(s)	No
Interface	USB 3.0 & eSATA
Bus Type	USB 3.0 & eSATA
Number of Drives	1

Drive Size	3.5in
Compatible Drive Types	SATA
Drive Installation	Removable
Number of internal 3.5 inch bays	1
Chipset ID	ASMedia - ASM1153E ASMedia - ASM1456

---

**Performance**

Maximum Data Transfer Rate	6 Gbps
Type and Rate	USB 3.0 - 5 Gbit/s
UASP Support	Yes
TRIM Support	Yes
4Kn Support	Yes
S.M.A.R.T. Support	Yes
Type and Rate	SATA III (6 Gbps)
Max Drive Capacity	Currently tested with up to 10TB 7200 RPM hard drives
Hot Swap Capability	Yes
Insertion Rating	50,000 cycles

---

**Connector(s)**

Drive Connectors	1 - SATA Data & Power Combo (7+15 pin)
Host Connectors	1 - USB 3.2 Type-B (9 pin, Gen 1, 5Gbps) 1 - eSATA (7 pin, Data)

---

**Software**

OS Compatibility	OS independent; No software or drivers required
------------------	---

---

**Special Notes / Requirements**

Note	Windows 7 and earlier Windows versions do not support TRIM
------	--

with USB to SATA devices.

---

**Indicators**

LED Indicators	1 - Power/Activity
----------------	--------------------

---

**Power**

Power Source	AC Adapter Included
Input Voltage	100 - 240 AC
Input Current	0.8A
Output Voltage	12V DC
Output Current	2000mA
Center Tip Polarity	Positive
Plug Type	M
Power Consumption (In Watts)	24

---

**Environmental**

Operating Temperature	0C to 50C (32F to 122F)
Storage Temperature	-20C to 55C (-4F to 131F)
Humidity	5% to 65%

---

**Physical Characteristics**

Color	Black
Material	Steel
Product Length	8.3 in [21.0 cm]
Product Width	5.3 in [13.4 cm]
Product Height	1.5 in [3.8 cm]
Weight of Product	18.4 oz [520.0 g]

---

**Packaging Information**

Package Quantity	1
------------------	---

---

Package Length	6.3 in [15.9 cm]
Package Width	9.6 in [24.4 cm]
Package Height	4.1 in [10.3 cm]
Shipping (Package) Weight	2.3 lb [1.0 kg]

---

#### What's in the Box

Included in Package	1 - drive enclosure
	1 - enclosure stand
	1 - USB 3.0 cable
	1 - eSATA cable
	1 - Power Adapter (NA)
	1 - quick-start guide

---

#### Warranty Information

Warranty	2 Years
----------	---------

---

*\*Product appearance and specifications are subject to change without notice.*

