


MSA Uncoded SFP+ Module - 10GBASE-LRM - 10GbE Multi Mode Fiber (MMF) Optic Transceiver - 10GE Gigabit Ethernet SFP+ - LC 200m - 1310nm - DDM

**Product ID:** SFP10GBLRMST

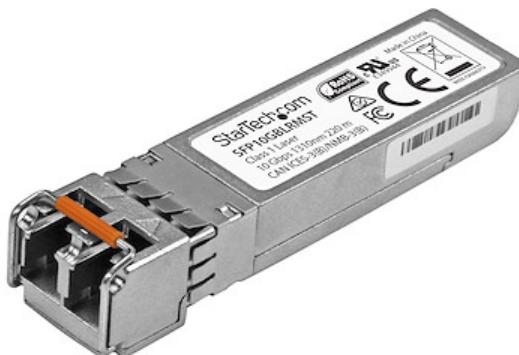

The SFP10GBLRMST is an MSA compliant fiber SFP transceiver that's designed, programmed and tested to work with 10GBASE-LRM compatible MSA switches and routers. The SFP+ transceiver module supports a maximum distance of up to 220 m (721 ft.) and delivers dependable 10 GbE connectivity over fiber cabling. **Technical Specifications:**

- Wavelength: 1310 nm
- Maximum Data Transfer Rate: 10 Gbps
- Type: Multi Mode Fiber
- Connection Type: LC Connector
- Maximum Transfer Distance: 220 m (721 ft.)
- Power Consumption: Less than 1 Watt
- DDM: Yes

This SFP+ fiber module is hot-swappable, making upgrades and replacements seamless by minimizing network disruptions.

All StarTech.com SFP & SFP+ transceiver modules are backed by a lifetime warranty and free lifetime multilingual technical support. StarTech.com offers a wide variety of SFP modules and direct-attach SFP Cables, providing the convenience and reliability you need to ensure dependable network performance.

## Certifications, Reports and Compatibility



## Applications

- Replace defective or damaged SFP+ modules
- Expand your network to remote segments

## Features

- 100% MSA UNCODED SFP+ TRANSCEIVER: Designed, programmed and tested to work with compatible MSA Compliant switches and routers to deliver reliable 10GbE connectivity
- TECHNICAL SPECS: 10GBASE-LRM 10Gbps Multi Mode (MMF) LC Connector 1310nm Digital Diagnostic Monitoring (DDM) Distances up to 200m (656ft)
- TESTED FOR COMPATIBILITY: Hot-swappable in MSA Compliant routers and switches; DDM support reports the transceiver's status to most SNMP network management tools.
- WORKS WITH MSA COMPLIANT SWITCHES: Works with switch models from Ubiquiti, D-Link, Netgear, Supermicro, TP-Link and more that accept uncoded modules
- THE IT PRO'S CHOICE: Designed and built for IT Professionals, this SFP module is backed for life (lifetime of module, not network switch), including free lifetime 24/5 multi-lingual technical assistance

---

### Hardware

Warranty	Lifetime
Compatible Brand	MSA Compliant
WDM	No
Industry Standards	IEEE 802.3ae 10GBASE-LRM

---

### Performance

Maximum Data Transfer Rate	10 Gbps
Max Transfer Distance	220m [722ft]
Type	Multi Mode
Wavelength	1310nm
Fiber Operating Mode	Full-Duplex

---

DDM	Yes
Compatible Networks	10 Gbps
Power Consumption (In Watts)	< 1 W

---

**Connector(s)**

Local Unit Connectors	1 - Fiber Optic LC Duplex
-----------------------	---------------------------

---

**Environmental**

Operating Temperature	0C to 70C (32F to 158F)
Storage Temperature	-40C to 85C (-40F to 185F)
Humidity	5~95% RH

---

**Physical Characteristics**

Color	Silver
Product Length	2.3 in [58.4 mm]
Product Width	0.5 in [1.4 cm]
Product Height	0.5 in [1.3 cm]
Weight of Product	0.8 oz [23.0 g]

---

**Packaging Information**

Package Length	4.6 in [11.7 cm]
Package Width	3.7 in [9.3 cm]
Package Height	1.3 in [3.3 cm]
Shipping (Package) Weight	2.3 oz [64.0 g]

---

**What's in the Box**

Included in Package	1 - SFP+ transceiver
---------------------	----------------------

---

**Warranty Information**

Warranty	Lifetime
----------	----------

*\*Product appearance and specifications are subject to change without notice.*

