

Dell EMC SFP-1G-LX Compatible SFP Module - 1000BASE-LX - 1GbE Single Mode Fiber SMF
Optic Transceiver - 1GE Gigabit Ethernet SFP - LC 10km - 1310nm - DDM

Product ID: SFP1GLXEMCST



The SFP1GLXEMCST is a Dell EMC SFP-1G-LX compatible fiber transceiver module that has been designed, programmed and tested to work with Dell EMC brand switches and routers. It delivers dependable 1 GbE connectivity over fiber cable, for 1000BASE-LX compliant networks, with a maximum distance of up to 10 km (6.2 mi).


Technical Specifications:

- Wavelength: 1310nm
- Maximum Data Transfer Rate: 1000 Mbps (1 Gbps)
- Type: Single Mode
- Connection Type: LC Connector
- Maximum Transfer Distance: 10 km (6.2 mi)
- MTBF: 53,972,659 hours
- Power Consumption: < 1.3W
- Digital Diagnostics Monitoring (DDM): Yes

This SFP fiber module is hot-swappable, making upgrades and replacements seamless by minimizing network disruptions.

All StarTech.com SFP & SFP+ transceiver modules are backed by a lifetime warranty and free lifetime multilingual technical support. StarTech.com offers a wide variety of SFP modules and direct-attach SFP cables, providing the convenience and reliability you need to ensure dependable network performance.

Certifications, Reports and Compatibility

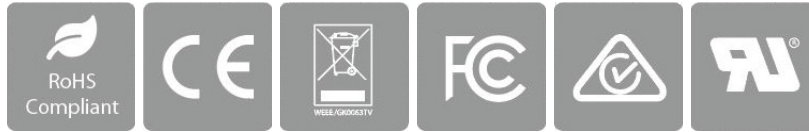

Applications

Features

- **100% DELL EMC SFP-1G-LX COMPATIBLE SFP TRANSCEIVER:** Designed, programmed and tested to work with compatible Dell EMC switches and routers to deliver reliable 1GbE connectivity
- **TECHNICAL SPECS:** 1000BASE-LX 1Gbps Single Mode (SMF) LC Connector 1310nm Digital Diagnostic Monitoring (DDM) Distances up to 10km (6.2mi)
- **TESTED FOR OEM HOST COMPATIBILITY:** Hot-swappable in Dell EMC routers and switches; DDM support reports the transceiver's status to most SNMP network management tools
- **WORKS WITH MSA COMPLIANT SWITCHES:** Also works with switch models from Ubiquiti, D-Link, Netgear, Supermicro, TP-Link and more that accept uncoded modules
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this SFP module is backed for life (lifetime of module, not network switch), including free lifetime 24/5 multi-lingual technical assistance.

Hardware

Warranty	Lifetime
Compatible Brand	Dell EMC
Industry Standards	IEEE 802.3z 1000BASE-LX

Performance

Maximum Data Transfer Rate	1.0 Gbps
Max Transfer Distance	10 km (6.2 mi)
Type	Single Mode
Wavelength	1310nm
	1310nm
Fiber Operating Mode	Full-Duplex

DDM	Yes
Compatible Networks	1000 Mbps (1 Gbps)
MTBF	53,972,659 hours
Power Consumption (In Watts)	< 1.3W

Physical Characteristics

Product Length	0.5 in [13.9 mm]
Product Width	2.3 in [5.8 cm]
Product Height	0.5 in [1.3 cm]
Weight of Product	1.1 oz [30.0 g]

Packaging Information

Package Length	4.5 in [11.4 cm]
Package Width	3.6 in [9.2 cm]
Package Height	1.3 in [3.3 cm]
Shipping (Package) Weight	1.6 oz [46.0 g]

What's in the Box

Included in Package	1 - SFP Transceiver
---------------------	---------------------

Warranty Information

Warranty	Lifetime
----------	----------

****Product appearance and specifications are subject to change without notice.***