

## 2 Port Black USB KVM Switch Kit with Audio and Cables

**Product ID:** SV211KUSB




The SV211KUSB 2 Port USB KVM Switch Kit with Audio and Cables lets you control two USB-enabled computers using a single keyboard, mouse and VGA monitor and offers both hotkey and top panel push-button operation for simple switching between connected computers.

Designed to integrate seamlessly into any environment, the USB KVM switch offers a small footprint design (roughly the size of a deck of playing cards) and draws power from the connected computers, so it doesn't require an external power supply.

A suitable solution for virtually any application, the USB KVM switch supports video resolutions of up to 2048 x 1536 as well as audio switching. The USB KVM switch includes two 4ft 2-in-1 VGA and USB Host Cables, providing everything needed for quick installation to provide a complete, out-of-the-box KVM solution.

Delivering dependable and convenient control of multiple computers from a single peripheral station, the KVM switch is backed by a StarTech.com 2-year warranty and free lifetime technical support.

### Certifications, Reports and Compatibility

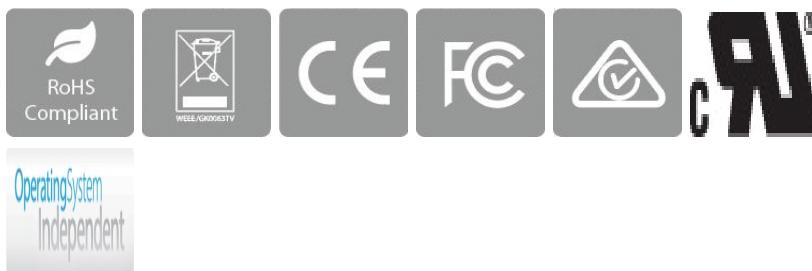

### Applications

- Control 2 USB-enabled computers using a single keyboard, mouse, and VGA monitor
- Applicable for call centers, help desks, education environments, home gamers, video editing, and PC enthusiasts
- Great for PC test/burn-in computer control saving the desk space required for two monitors, keyboards and mice
- Dual system control for single user workstations, increasing user productivity in the office

## Features

- Cables (4 ft.) included
- Maximum resolution: 2048 x 1536
- Switching type: Hotkey, push-button
- Includes audio support for a complete switching solution
- Small footprint design
- USB Powered - No external adapter required

---

### Hardware

Warranty	2 Years
Audio	Yes
KVM Ports	2
PC Interface	USB
PC Video Type	VGA
Number of Monitors Supported	1
Rack-Mountable	No
Cables Included	Yes
Daisy-Chain	No

---

### Performance

On-Screen Display	No
IP Control	No
Hot-Key Selection	Yes

Maximum Analog Resolutions	2048x1536 @60Hz
Maximum Number of Users	1
Port Selection Support	Push Button and Hotkeys

---

**Connector(s)**

Console Interface(s)	2 - 3.5 mm Mini-Jack (3 Position)
	2 - USB 2.0 Type-A (4 pin, 480Mbps)
	1 - VGA (15 pin, High Density D-Sub)
Host Connectors	2 - VGA (15 pin, High Density D-Sub)
	2 - USB Mini-B (5 pin)

---

**Software**

OS Compatibility	OS independent; No software or drivers required
------------------	---

---

**Power**

Power Source	USB-Powered
Input Voltage	5V DC
Output Voltage	5 DC

---

**Physical Characteristics**

Color	Black
Material	Plastic
Cable Length	4.0 ft [1.2 m]
Product Length	3.8 in [9.7 cm]
Product Width	2.6 in [6.6 cm]
Product Height	0.9 in [2.4 cm]
Product Depth	2.4 in [60 mm]
Weight of Product	3.3 oz [94 g]

---

**Packaging Information**

Package Quantity	1
Package Length	8.6 in [21.9 cm]
Package Width	5.2 in [13.3 cm]
Package Height	3.5 in [9.0 cm]
Shipping (Package) Weight	1.4 lb [0.6 kg]

---

#### What's in the Box

Included in Package	1 - 2 Port KVM Switch
	2 - 4ft. VGA USB KVM Cable
	2 - 4ft. Audio Cable (3.5mm speaker/mic)
	1 - Driver CD
	1 - Instruction Manual

---

#### Warranty Information

Warranty	2 Years
----------	---------

---

*\*Product appearance and specifications are subject to change without notice.*

