


Long Micro-USB Charge-and-Sync Cable M/M - 24 AWG - 3 m (10 ft.)

**Product ID:** USBAUB3MBK

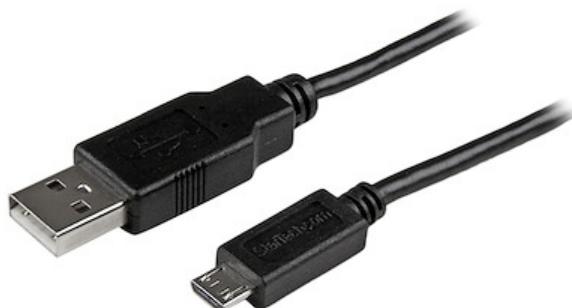

Tired of being attached to the wall when charging and using your phone or tablet?

The USBAUB3MBK Micro USB cable offers 3 meters in cable length so you can charge your device in comfort and from a distance. Plus, the cable offers a slim design that lets you plug into your device without having to take it out of its case for every charge and sync.

Charge your device even while you're taking notes in a boardroom, catching up on emails in a hotel room, or reading in a coffee shop. The 3-meter long charge cable overcomes distance restrictions and lets you stay connected even while charging.

Provide full charging power, with no loss of charge time, even at distances of up to 10 feet (3 meters) away from your charger. The heavier gauge (24/30 AWG) wire lets you charge your mobile devices without slowing down charge time - allowing you to stay connected and charge at the same speed as you would using a shorter cable.

Stop removing the case from your phone or tablet every time you charge or sync your device. The cable offers a slim Micro USB connector molding that plugs into your device even while it's inside a protective case.

Designed and constructed for maximum durability, this high quality USB-A to Micro-B cable is backed by StarTech.com's Lifetime Warranty.

## Certifications, Reports and Compatibility



## Applications

- Charge and sync your Micro USB-equipped mobile digital devices

## Features

- Offers 3m in cable length
- Slim Micro USB connector molding
- Aluminum-mylar foil with braided shielding
- Supports high-speed USB data transfer rates of up to 480 Mbps

### Hardware

Warranty	Lifetime
Connector Plating	Nickel
Cable Jacket Material	PVC - Polyvinyl Chloride
Cable Shield Material	Aluminum-Mylar Foil with Braid

### Performance

Type and Rate	USB 2.0 - 480 Mbit/s
---------------	----------------------

### Connector(s)

Connector A	1 - USB 2.0 Type-A (4 pin, 480Mbps)
Connector B	1 - USB Micro-B (5 pin)

### Special Notes / Requirements

Note	Micro USB connector molding width is 10mm and height is 6mm (please see drawing)
------	--

### Environmental

Operating Temperature	-20C to 80C (4F to 176F)
Storage Temperature	28C(5C) / 82F(9F)
Humidity	0%RH ~ 95%RH

### Physical Characteristics

Color	Black
Connector Style	Straight

---

Wire Gauge	24/30 AWG
Cable Length	9.8 ft [3 m]
Product Length	9.8 ft [3 m]
Weight of Product	2.2 oz [61.3 g]

---

**Packaging Information**

Package Quantity	1
Package Length	6.3 in [15.9 cm]
Package Width	5.0 in [12.8 cm]
Package Height	0.7 in [1.7 cm]
Shipping (Package) Weight	2.4 oz [68.0 g]

---

**What's in the Box**

Included in Package	1 - 3m Mobile Charge Sync Micro USB Cable - A to Micro B
---------------------	--

---

**Warranty Information**

Warranty	Lifetime
----------	----------

---

*\*Product appearance and specifications are subject to change without notice.*

