

# MB earthing tapes

made of flexible E-Cu stranded wires with connecting end pads



Manufactured with highly flexible E-Cu stranded wires with connecting end pads made of tinned copper strips.

The minimum transition and connecting resistance makes them perfectly suitable for use as earthing tapes.

Earthing Tapes are available with M4, M5, M6, M8 or M10 connections and in some sizes with both connection sizes combined.

The earthing tapes are also available with green and yellow shrink sleeve (MB-GG). This provides clear visual colour identification.

**UL Product iQ:** [Download PDF](#)

(except all MB-GG as well as part no. 32868 / 32870 / 32872)



RoHS compliant



Cross-section	Current load
6 mm <sup>2</sup>	67 - 80 A
10 mm <sup>2</sup>	89 - 106 A
16 mm <sup>2</sup>	132 - 157 A
25 mm <sup>2</sup>	177 - 210 A
35 mm <sup>2</sup>	230 - 275 A
50 mm <sup>2</sup>	280 - 350 A
70 mm <sup>2</sup>	338 - 403 A

## Specifications

<b>Material</b>	Cu-ETP Shrink sleeve: Polyolefin
<b>Mounting options</b>	Screw type mounting

## Advantages & benefits

- Available in a variety of lengths and cross-sections
- Low impedances
- UL listed

## Product types & sizes

<b>MB 6 C-T 100 M4</b>	Part No.	<b>32695</b>	Height	<b>2 mm</b>
	EAN	<b>4251269324253</b>	Hole size	<b>M4</b>
	Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
	Length	<b>100 mm</b>	Current load	<b>67 - 80 A</b>
	Length L1	<b>14 mm</b>		
	Length L2	<b>113 mm</b>		
	Width	<b>10 mm</b>		

<b>MB 6 C-T 100 M6</b>	Part No.	<b>32700</b>	Height	<b>2 mm</b>
	EAN	<b>4251269301407</b>	Hole size	<b>M6</b>
	Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
	Length	<b>100 mm</b>	Current load	<b>67 - 80 A</b>
	Length L1	<b>14 mm</b>		
	Length L2	<b>113 mm</b>		
	Width	<b>10 mm</b>		

**MB 10 C-T 100 M6+M4**

Part No.	<b>39711</b>	Height	<b>3 mm</b>
EAN		Hole size	<b>M4/ M6</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>100 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>120 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 100 M6**

Part No.	<b>32730</b>	Height	<b>3 mm</b>
EAN	<b>4251269301476</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>100 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>120 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 100 M8**

Part No.	<b>32731</b>	Height	<b>3 mm</b>
EAN	<b>4251269301483</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>100 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>120 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 100 M6**

Part No.	<b>32760</b>	Height	<b>3 mm</b>
EAN	<b>4251269301605</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>100 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>120 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 100 M6+M8**

Part No.	<b>32758</b>	Height	<b>3 mm</b>
EAN	<b>4251269322099</b>	Hole size	<b>M6/ M8</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>100 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>120 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 100 M8**

Part No.	<b>32761</b>	Height	<b>3 mm</b>
EAN	<b>4251269301612</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>100 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>120 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 100 M10**

Part No.	<b>32759</b>	Height	<b>3 mm</b>
EAN	<b>4251269322303</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>100 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>120 mm</b>		
Width	<b>16 mm</b>		

---

**MB 25 C-T 100 M10**

Part No.	<b>32800</b>	Height	<b>4 mm</b>
EAN	<b>4251269301766</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
Length	<b>100 mm</b>	Current load	<b>177 - 210 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>123 mm</b>		
Width	<b>21 mm</b>		

---

**MB 6 C-T 150 M4**

Part No.	<b>39710</b>	Height	<b>3 mm</b>
EAN		Hole size	<b>M4</b>
Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>67 - 80 A</b>
Length L1	<b>14 mm</b>		
Length L2	<b>163 mm</b>		
Width	<b>10 mm</b>		

---

**MB 6 C-T 150 M6**

Part No.	<b>32701</b>	Height	<b>2 mm</b>
EAN	<b>4251269301414</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>67 - 80 A</b>
Length L1	<b>14 mm</b>		
Length L2	<b>163 mm</b>		
Width	<b>10 mm</b>		

---

**MB 10 C-T 150 M5**

Part No.	<b>32709</b>	Height	<b>3 mm</b>
EAN	<b>4251269322297</b>	Hole size	<b>M5</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>170 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 150 M5+M6**

Part No.	<b>32746</b>	Height	<b>3 mm</b>
EAN	<b>4251269322082</b>	Hole size	<b>M5/ M6</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>170 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 150 M8**

Part No.	<b>32732</b>	Height	<b>3 mm</b>
EAN	<b>4251269301490</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>170 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 150 M6**

Part No.	<b>32762</b>	Height	<b>3 mm</b>
EAN	<b>4251269301629</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>170 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 150 M8**

Part No.	<b>32763</b>	Height	<b>3 mm</b>
EAN	<b>4251269301636</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>170 mm</b>		
Width	<b>16 mm</b>		

---

**MB 25 C-T 150 M10**

Part No.	<b>32801</b>	Height	<b>4 mm</b>
EAN	<b>4251269301773</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>177 - 210 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>173 mm</b>		
Width	<b>21 mm</b>		

---

**MB 50 C-T 150 M10**

Part No.	<b>32847</b>	Height	<b>5 mm</b>
EAN	<b>4251269322198</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>50 mm<sup>2</sup></b>
Length	<b>150 mm</b>	Current load	<b>280 - 350 A</b>
Length L1	<b>25 mm</b>		
Length L2	<b>177 mm</b>		
Width	<b>26 mm</b>		

---

**MB 6 C-T 200 M4**

Part No.	<b>32707</b>	Height	<b>2 mm</b>
EAN	<b>4251269322273</b>	Hole size	<b>M4</b>
Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>67 - 80 A</b>
Length L1	<b>14 mm</b>		
Length L2	<b>213 mm</b>		
Width	<b>10 mm</b>		

---

**MB 6 C-T 200 M6**

Part No.	<b>32702</b>	Height	<b>2 mm</b>
EAN	<b>4251269301421</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>67 - 80 A</b>
Length L1	<b>14 mm</b>		
Length L2	<b>213 mm</b>		
Width	<b>10 mm</b>		

---

**MB 10 C-T 200 M5**

Part No.	<b>32744</b>	Height	<b>3 mm</b>
EAN	<b>4251269322266</b>	Hole size	<b>M5</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 200 M6**

Part No.	<b>32733</b>	Height	<b>3 mm</b>
EAN	<b>4251269301506</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 200 M6+M8**

Part No.	<b>32741</b>	Height	<b>3 mm</b>
EAN	<b>4251269301575</b>	Hole size	<b>M6/ M8</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 200 M8**

Part No.	<b>32734</b>	Height	<b>3 mm</b>
EAN	<b>4251269301513</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>89 - 106A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 200 M5+M6**

Part No.	<b>32776</b>	Height	<b>3 mm</b>
EAN	<b>4251269322105</b>	Hole size	<b>M5/ M6</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 200 M6**

Part No.	<b>32764</b>	Height	<b>3 mm</b>
EAN	<b>4251269301643</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 200 M6+M8**

Part No.	<b>32773</b>	Height	<b>3 mm</b>
EAN	<b>4251269301735</b>	Hole size	<b>M6/ M8</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 200 M8**

Part No.	<b>32765</b>	Height	<b>3 mm</b>
EAN	<b>4251269301650</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

---

**MB 25 C-T 200 M8**

Part No.	<b>32802</b>	Height	<b>4 mm</b>
EAN	<b>4251269301780</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
Length	<b>250 mm</b>	Current load	<b>177 - 210 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>223 mm</b>		
Width	<b>21 mm</b>		

---

**MB 25 C-T 200 M10**

Part No.	<b>32803</b>	Height	<b>4 mm</b>
EAN	<b>4251269301797</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>177 - 210 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>223 mm</b>		
Width	<b>21 mm</b>		

---

**MB 35 C-T 200 M10**

Part No.	<b>32823</b>	Height	<b>4,5 mm</b>
EAN	<b>4251269322167</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>35 mm<sup>2</sup></b>
Length	<b>200 mm</b>	Current load	<b>230 - 275 A</b>
Length L1	<b>25 mm</b>		
Length L2	<b>227 mm</b>		
Width	<b>26 mm</b>		

---

**MB 50 C-T 200 M10**

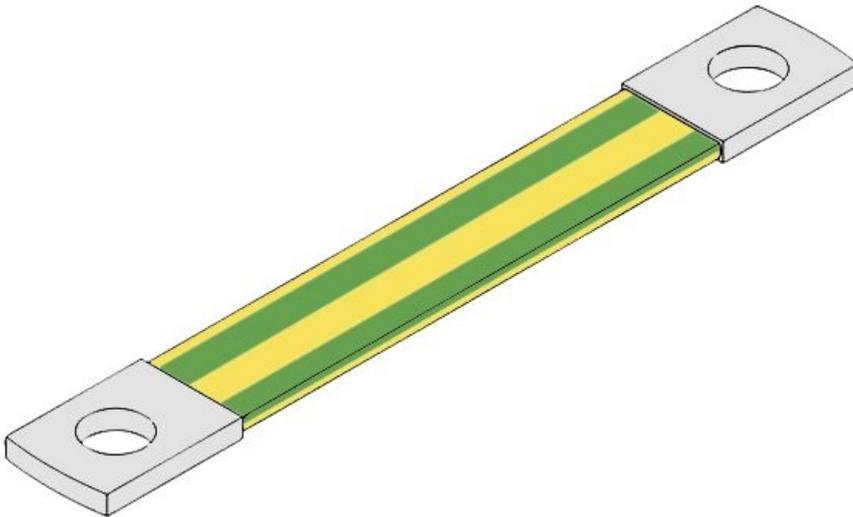
Part No. **32848**  
 EAN **4251269322204**  
 Package quantity **1**  
 Length **200 mm**  
 Length L1 **25 mm**  
 Length L2 **227 mm**  
 Width **26 mm**

Height **5 mm**  
 Hole size **M10**  
 Cross-section **50 mm<sup>2</sup>**  
 Current load **280 - 350 A**

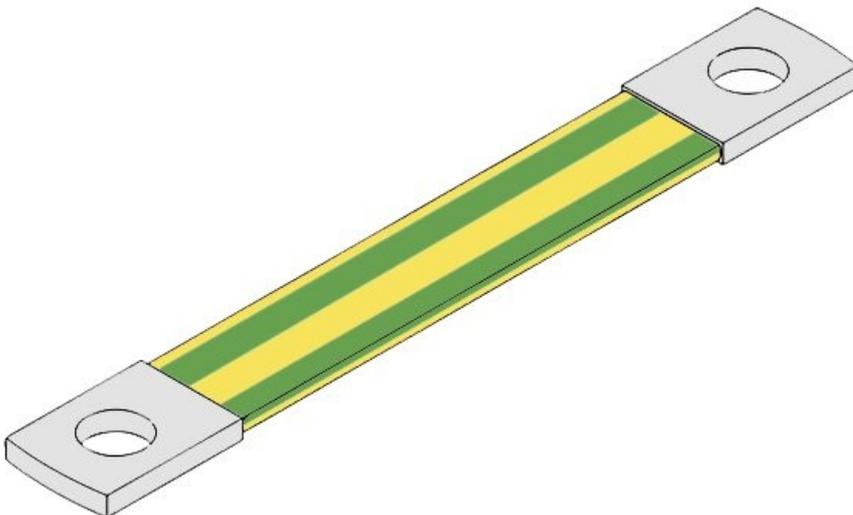
**MB 70 C-T 200 M10**

Part No. **32868**  
 EAN **4251269322235**  
 Package quantity **1**  
 Length **200 mm**  
 Length L1 **25 mm**  
 Length L2 **227 mm**  
 Width **26 mm**

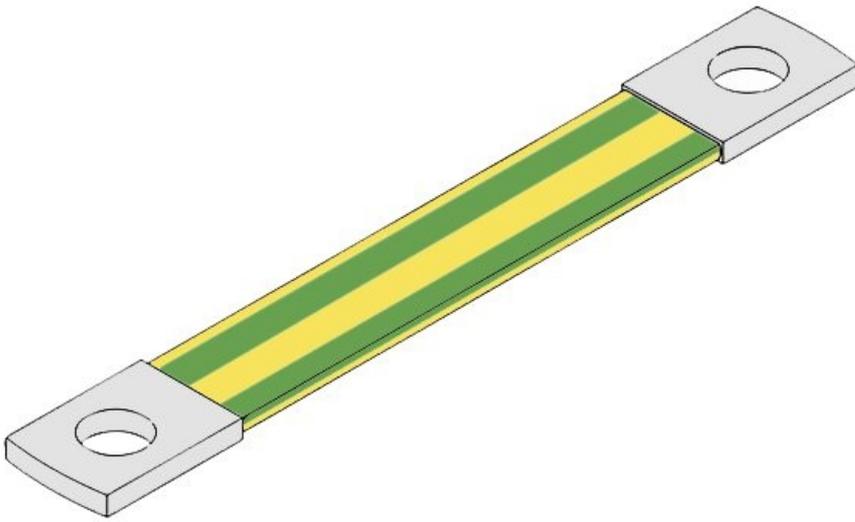
Height **6,2 mm**  
 Hole size **M10**  
 Cross-section **70 mm<sup>2</sup>**  
 Current load **338 - 403 A**

**MB 6 C-T 200 M4 GG**

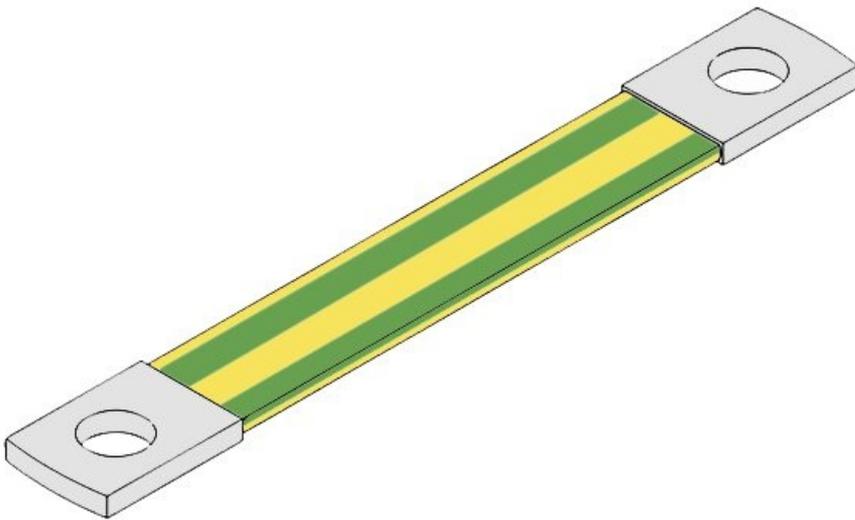
Part No. **32707.800** Height **2 mm**  
 EAN **4251269338** Hole size **M4**  
**687** Cross-section **6 mm<sup>2</sup>**  
 Package quantity **10** Current load **67 - 80 A**  
 Length **200 mm**  
 Length L1 **14 mm**  
 Length L2 **213 mm**  
 Width **10 mm**

**MB 6 C-T 200 M6 GG**

Part No. **32702.800** Height **2 mm**  
 EAN **4251269338** Hole size **M6**  
**694** Cross-section **6 mm<sup>2</sup>**  
 Package quantity **10** Current load **67 - 80 A**  
 Length **200 mm**  
 Length L1 **14 mm**  
 Length L2 **213 mm**  
 Width **10 mm**

**MB 16 C-T 200 M6 GG**

Part No.	<b>32764.800</b>	Height	<b>3 mm</b>
EAN	<b>4251269338</b>	Hole size	<b>M6</b>
	<b>649</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Package quantity	<b>10</b>	Current load	<b>132 - 157 A</b>
Length	<b>200 mm</b>		
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

**MB 16 C-T 200 M8 GG**

Part No.	<b>32765.800</b>	Height	<b>3 mm</b>
EAN	<b>4251269338</b>	Hole size	<b>M8</b>
	<b>656</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Package quantity	<b>10</b>	Current load	<b>132 - 157 A</b>
Length	<b>200 mm</b>		
Length L1	<b>22 mm</b>		
Length L2	<b>220 mm</b>		
Width	<b>16 mm</b>		

**MB 6 C-T 250 M6**

Part No.	<b>32706</b>
EAN	<b>4251269301469</b>
Package quantity	<b>1</b>
Length	<b>250 mm</b>
Length L1	<b>14 mm</b>
Length L2	<b>263 mm</b>
Width	<b>10 mm</b>

Height	<b>2 mm</b>
Hole size	<b>M6</b>
Cross-section	<b>6 mm<sup>2</sup></b>
Current load	<b>67 - 80 A</b>

**MB 10 C-T 250 M6+M8**

Part No.	<b>32742</b>
EAN	<b>4251269301582</b>
Package quantity	<b>1</b>
Length	<b>250 mm</b>
Length L1	<b>22 mm</b>
Length L2	<b>260 mm</b>
Width	<b>16 mm</b>

Height	<b>3 mm</b>
Hole size	<b>M6/ M8</b>
Cross-section	<b>10 mm<sup>2</sup></b>
Current load	<b>89 - 106 A</b>

**MB 16 C-T 250 M6+M8**

Part No.	<b>32774</b>	Height	<b>3 mm</b>
EAN	<b>4251269301742</b>	Hole size	<b>M6/ M8</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>250 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>270 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 250 M8**

Part No.	<b>32766</b>	Height	<b>3 mm</b>
EAN	<b>4251269301667</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>250 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>270 mm</b>		
Width	<b>16 mm</b>		

---

**MB 25 C-T 250 M8**

Part No.	<b>32804</b>	Height	<b>4 mm</b>
EAN	<b>4251269301803</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
Length	<b>250 mm</b>	Current load	<b>177 - 210 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>273 mm</b>		
Width	<b>21 mm</b>		

---

**MB 25 C-T 250 M10**

Part No.	<b>32805</b>	Height	<b>4 mm</b>
EAN	<b>4251269301810</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
Length	<b>250 mm</b>	Current load	<b>177 - 210 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>273 mm</b>		
Width	<b>21 mm</b>		

---

**MB 35 C-T 250 M10**

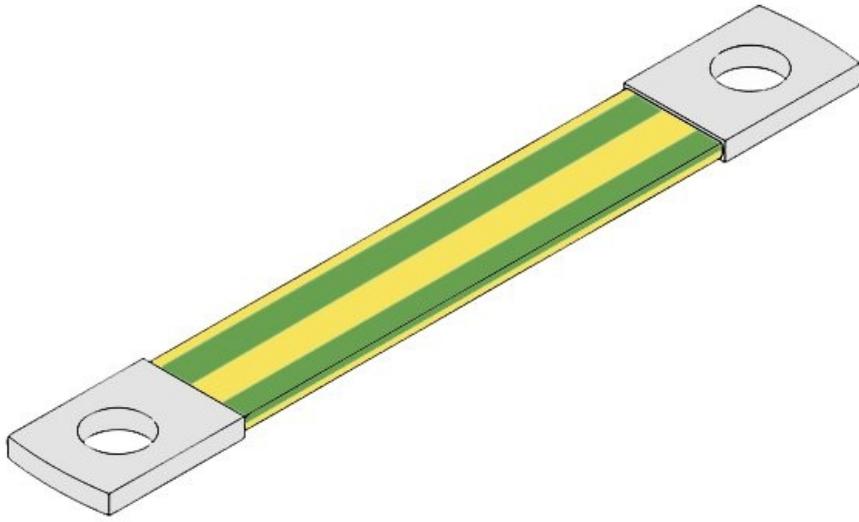
Part No.	<b>32824</b>	Height	<b>4,5 mm</b>
EAN	<b>4251269322174</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>35 mm<sup>2</sup></b>
Length	<b>250 mm</b>	Current load	<b>230 - 275 A</b>
Length L1	<b>25 mm</b>		
Length L2	<b>277 mm</b>		
Width	<b>26 mm</b>		

---

**MB 50 C-T 250 M10**

Part No.	<b>32849</b>	Height	<b>5 mm</b>
EAN	<b>4251269322211</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>50 mm<sup>2</sup></b>
Length	<b>250 mm</b>	Current load	<b>280 - 350 A</b>
Length L1	<b>25 mm</b>		
Length L2	<b>277 mm</b>		
Width	<b>16 mm</b>		

---



Part No.	<b>32766.800</b>	Height	<b>3 mm</b>
EAN	<b>4251269338</b>	Hole size	<b>M8</b>
	<b>663</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Package quantity	<b>10</b>	Current load	<b>132 - 157 A</b>
Length	<b>250 mm</b>		
Length L1	<b>22 mm</b>		
Length L2	<b>270 mm</b>		
Width	<b>16 mm</b>		

MB 6 C-T 300 M6

Part No.	<b>32703</b>	Height	<b>2 mm</b>
EAN	<b>4251269301438</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
Length	<b>300 mm</b>	Current load	<b>67 - 80 A</b>
Length L1	<b>14 mm</b>		
Length L2	<b>313 mm</b>		
Width	<b>10 mm</b>		

MB 10 C-T 300 M6

Part No.	<b>32735</b>	Height	<b>3 mm</b>
EAN	<b>4251269301520</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>300 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>320 mm</b>		
Width	<b>16 mm</b>		

MB 10 C-T 300 M6+M8

Part No.	<b>32743</b>	Height	<b>3 mm</b>
EAN	<b>4251269301599</b>	Hole size	<b>M6/ M8</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>300 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>320 mm</b>		
Width	<b>16 mm</b>		

MB 10 C-T 300 M8

Part No.	<b>32736</b>	Height	<b>3 mm</b>
EAN	<b>4251269301537</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>300 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>320 mm</b>		
Width	<b>16 mm</b>		

---

<b>MB 16 C-T 300 M6</b>	Part No.	<b>32767</b>	Height	<b>3 mm</b>
	EAN	<b>4251269301674</b>	Hole size	<b>M6</b>
	Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
	Length	<b>300 mm</b>	Current load	<b>132 - 157 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>320 mm</b>		
	Width	<b>16 mm</b>		

---

<b>MB 16 C-T 300 M6+M8</b>	Part No.	<b>32775</b>	Height	<b>3 mm</b>
	EAN	<b>4251269301759</b>	Hole size	<b>M6/ M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
	Length	<b>300 mm</b>	Current load	<b>132 - 157 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>320 mm</b>		
	Width	<b>16 mm</b>		

---

<b>MB 16 C-T 300 M8</b>	Part No.	<b>32768</b>	Height	<b>3 mm</b>
	EAN	<b>4251269301681</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
	Length	<b>300 mm</b>	Current load	<b>132 - 157 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>320 mm</b>		
	Width	<b>16 mm</b>		

---

<b>MB 25 C-T 300 M6</b>	Part No.	<b>32816</b>	Height	<b>4 mm</b>
	EAN	<b>4251269333187</b>	Hole size	<b>M6</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>300 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>323 mm</b>		
	Width	<b>21 mm</b>		

---

<b>MB 25 C-T 300 M8</b>	Part No.	<b>32806</b>	Height	<b>4 mm</b>
	EAN	<b>4251269301827</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>300 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>323 mm</b>		
	Width	<b>21 mm</b>		

---

<b>MB 25 C-T 300 M8+M10</b>	Part No.	<b>32817</b>	Height	<b>4 mm</b>
	EAN	<b>4251269333194</b>	Hole size	<b>M8/ M10</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>300 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>323 mm</b>		
	Width	<b>21 mm</b>		

---

<b>MB 25 C-T 300 M10</b>	Part No.	<b>32807</b>	Height	<b>4 mm</b>
	EAN	<b>4251269301834</b>	Hole size	<b>M10</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>300 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>323 mm</b>		
	Width	<b>21 mm</b>		

---

**MB 35 C-T 300 M10**

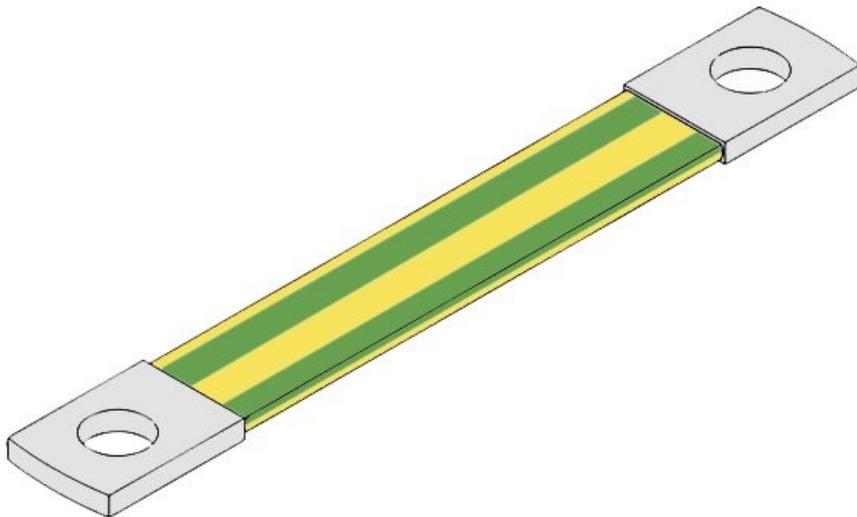
Part No.	<b>32825</b>	Height	<b>4,5 mm</b>
EAN	<b>4251269322181</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>35 mm<sup>2</sup></b>
Length	<b>300 mm</b>	Current load	<b>230 - 275 A</b>
Length L1	<b>25 mm</b>		
Length L2	<b>327 mm</b>		
Width	<b>26 mm</b>		

**MB 50 C-T 300 M10**

Part No.	<b>32850</b>	Height	<b>5 mm</b>
EAN	<b>4251269322228</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>50 mm<sup>2</sup></b>
Length	<b>300 mm</b>	Current load	<b>280 - 350 A</b>
Length L1	<b>25 mm</b>		
Length L2	<b>327 mm</b>		
Width	<b>26 mm</b>		

**MB 70 C-T 300 M10**

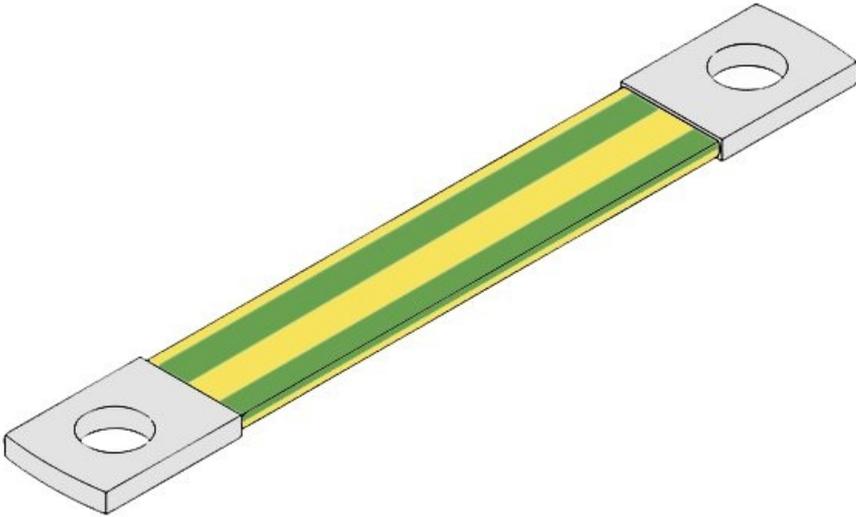
Part No.	<b>32870</b>	Height	<b>6,2 mm</b>
EAN	<b>4251269322242</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>70 mm<sup>2</sup></b>
Length	<b>300 mm</b>	Current load	<b>338 - 403 A</b>
Length L1	<b>25 mm</b>		
Length L2	<b>327 mm</b>		
Width	<b>26 mm</b>		

**MB 16 C-T 300 M6 GG**

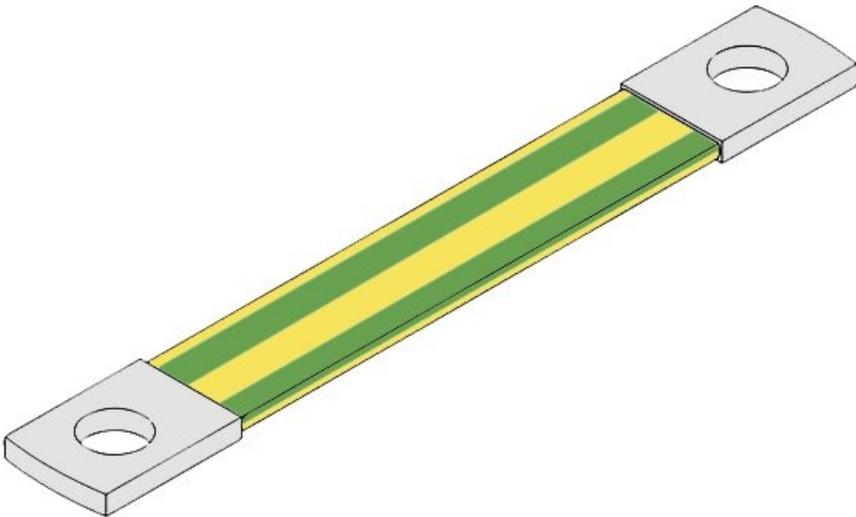
Part No.	<b>32767.800</b>	Height	<b>3 mm</b>
EAN	<b>42512693338</b>	Hole size	<b>M6</b>
Package quantity	<b>10</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>300 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>320 mm</b>		
Width	<b>16 mm</b>		

**MB 16 C-T 300 M8 GG**

Part No.	<b>32768.800</b>	Height	<b>3 mm</b>
EAN	<b>4251269338</b>	Hole size	<b>M8</b>
	<b>700</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Package quantity	<b>10</b>	Current load	<b>132 - 157 A</b>
Length	<b>300 mm</b>		
Length L1	<b>22 mm</b>		
Length L2	<b>320 mm</b>		
Width	<b>16 mm</b>		

**MB 25 C-T 300 M8 GG**

Part No.	<b>32806.800</b>	Height	<b>4 mm</b>
EAN	<b>4251269338</b>	Hole size	<b>M8</b>
	<b>670</b>	Cross-section	<b>25 mm<sup>2</sup></b>
Package quantity	<b>10</b>	Current load	<b>177 - 210 A</b>
Length	<b>300 mm</b>		
Length L1	<b>22 mm</b>		
Length L2	<b>323 mm</b>		
Width	<b>21 mm</b>		

**MB 16 C-T 350 M5+M6**

Part No.	<b>32777</b>	Height	<b>3 mm</b>
EAN	<b>4251269322112</b>	Hole size	<b>M5/ M6</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>350 mm</b>	Current load	<b>132 - 157</b>
Length L1	<b>22 mm</b>		
Length L2	<b>370 mm</b>		
Width	<b>16 mm</b>		

**MB 16 C-T 350 M8**

Part No.	<b>32769</b>	Height	<b>3 mm</b>
EAN	<b>4251269301698</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>350 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>370 mm</b>		
Width	<b>16 mm</b>		

---

**MB 25 C-T 350 M10**

Part No.	<b>32808</b>	Height	<b>4 mm</b>
EAN	<b>4251269301841</b>	Hole size	<b>M10</b>
Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
Length	<b>350 mm</b>	Current load	<b>177 - 210 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>373 mm</b>		
Width	<b>21 mm</b>		

---

**MB 6 C-T 400 M6**

Part No.	<b>32704</b>	Height	<b>2 mm</b>
EAN	<b>4251269301445</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
Length	<b>400 mm</b>	Current load	<b>67 - 80 A</b>
Length L1	<b>14 mm</b>		
Length L2	<b>413 mm</b>		
Width	<b>10 mm</b>		

---

**MB 10 C-T 400 M4**

Part No.	<b>32878</b>	Height	<b>3 mm</b>
EAN	<b>4251269324130</b>	Hole size	<b>M4</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>400 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>420 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 400 M6**

Part No.	<b>32737</b>	Height	<b>3 mm</b>
EAN	<b>4251269301544</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>400 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>420 mm</b>		
Width	<b>16 mm</b>		

---

**MB 10 C-T 400 M8**

Part No.	<b>32738</b>	Height	<b>3 mm</b>
EAN	<b>4251269301551</b>	Hole size	<b>M8</b>
Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
Length	<b>400 mm</b>	Current load	<b>89 - 106 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>420 mm</b>		
Width	<b>16 mm</b>		

---

**MB 16 C-T 400 M6**

Part No.	<b>32873</b>	Height	<b>3 mm</b>
EAN	<b>4251269322129</b>	Hole size	<b>M6</b>
Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
Length	<b>400 mm</b>	Current load	<b>132 - 157 A</b>
Length L1	<b>22 mm</b>		
Length L2	<b>420 mm</b>		
Width	<b>16 mm</b>		

---

<b>MB 16 C-T 400 M8</b>	Part No.	<b>32770</b>	Height	<b>3 mm</b>
	EAN	<b>4251269301704</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
	Length	<b>400 mm</b>	Current load	<b>132 - 157 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>420 mm</b>		
	Width	<b>16 mm</b>		

---

<b>MB 25 C-T 400 M8</b>	Part No.	<b>32809</b>	Height	<b>4 mm</b>
	EAN	<b>4251269301858</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>400 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>423 mm</b>		
	Width	<b>21 mm</b>		

---

<b>MB 35 C-T 400 M8</b>	Part No.	<b>32886</b>	Height	<b>4,5 mm</b>
	EAN	<b>4251269335976</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>35 mm<sup>2</sup></b>
	Length	<b>400 mm</b>	Current load	<b>230 - 275 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>423 mm</b>		
	Width	<b>26 mm</b>		

---

<b>MB 6 C-T 500 M6</b>	Part No.	<b>32705</b>	Height	<b>2 mm</b>
	EAN	<b>4251269301452</b>	Hole size	<b>M6</b>
	Package quantity	<b>1</b>	Cross-section	<b>6 mm<sup>2</sup></b>
	Length	<b>500 mm</b>	Current load	<b>67 - 80 A</b>
	Length L1	<b>14 mm</b>		
	Length L2	<b>513 mm</b>		
	Width	<b>10 mm</b>		

---

<b>MB 10 C-T 500 M6</b>	Part No.	<b>32739</b>	Height	<b>3 mm</b>
	EAN	<b>4251269301568</b>	Hole size	<b>M6</b>
	Package quantity	<b>1</b>	Cross-section	<b>10 mm<sup>2</sup></b>
	Length	<b>500 mm</b>	Current load	<b>89 - 106 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>520 mm</b>		
	Width	<b>16 mm</b>		

---

<b>MB 16 C-T 500 M8</b>	Part No.	<b>32771</b>	Height	<b>3 mm</b>
	EAN	<b>4251269301711</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
	Length	<b>500 mm</b>	Current load	<b>132 - 157 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>520 mm</b>		
	Width	<b>16 mm</b>		

---

<b>MB 25 C-T 500 M8</b>	Part No.	<b>32810</b>	Height	<b>4 mm</b>
	EAN	<b>4251269301865</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>500 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>523 mm</b>		
	Width	<b>21 mm</b>		

---

<b>MB 25 C-T 500 M10</b>	Part No.	<b>32812</b>	Height	<b>4 mm</b>
	EAN	<b>4251269322143</b>	Hole size	<b>M10</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>500 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>523 mm</b>		
	Width	<b>21 mm</b>		

---

<b>MB 70 C-T 500 M10</b>	Part No.	<b>32872</b>	Height	<b>6,2 mm</b>
	EAN	<b>4251269322259</b>	Hole size	<b>M10</b>
	Package quantity	<b>1</b>	Cross-section	<b>70 mm<sup>2</sup></b>
	Length	<b>500 mm</b>	Current load	<b>338 - 403 A</b>
	Length L1	<b>25 mm</b>		
	Length L2	<b>527 mm</b>		
	Width	<b>26 mm</b>		

---

<b>MB 16 C-T 600 M8</b>	Part No.	<b>32772</b>	Height	<b>3 mm</b>
	EAN	<b>4251269301728</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
	Length	<b>600 mm</b>	Current load	<b>132 - 157 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>620 mm</b>		
	Width	<b>16 mm</b>		

---

<b>MB 25 C-T 600 M8</b>	Part No.	<b>32811</b>	Height	<b>4 mm</b>
	EAN	<b>4251269301872</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>600 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>623 mm</b>		
	Width	<b>21 mm</b>		

---

<b>MB 25 C-T 800 M8</b>	Part No.	<b>32815</b>	Height	<b>4 mm</b>
	EAN	<b>4251269322150</b>	Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>25 mm<sup>2</sup></b>
	Length	<b>800 mm</b>	Current load	<b>177 - 210 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>823 mm</b>		
	Width	<b>21 mm</b>		

---

<b>MB 16 C-T 1000 M8</b>	Part No.	<b>32778</b>	Height	<b>4 mm</b>
	EAN		Hole size	<b>M8</b>
	Package quantity	<b>1</b>	Cross-section	<b>16 mm<sup>2</sup></b>
	Length	<b>1.000 mm</b>	Current load	<b>132 - 157 A</b>
	Length L1	<b>22 mm</b>		
	Length L2	<b>823 mm</b>		
	Width	<b>21 mm</b>		

---

