

Standard*Image for illustrative purpose only*

Summary

[Request a quote](#)[SE series](#)

Size	3E
Series	E - Outdoor Stepped Insert

Technical details

Electrical Configuration

Footprint IPC Class3 compatibility	No
------------------------------------	----


Form & Material

Shell style / Model id	BFA - Cap for plug
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Keying	No keying
Colour	Grey
Weight	33.7 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-50°C / +135°C
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

Drawings

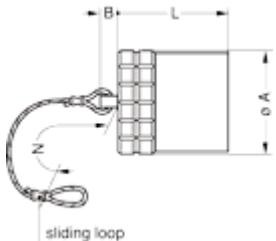

No keying

Dimensions

	A	B	L	N
mm.	23	6	22	120
in.	0.91	0.24	0.87	4.72

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/bfa-3e-100-nas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.