

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

BKT series

Plug	Plug - Straight
Size	3K
Series	K - Outdoor keyed

Technical details



Form & Material

Shell style / Model id	BHG - Plug cap nut fixing or flange
Plug	Straight
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	32.92 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-50°C / +135°C
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

Drawings

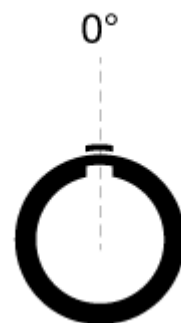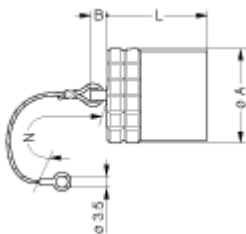

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bhg-3k-100-nas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	L	N
mm.	23	6	22	120
in.	0.91	0.24	0.87	4.72