

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[BKT series](#)

Size	0B
Series	B - Indoor keyed

Technical details


Form & Material

Shell style / Model id	BRD - Cap for free receptacle
Housing material	POM (Polyoxymethylene) shell without treatment, silicone gasket
Keying	No keying
Weight	0.55 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP61
Temperature range	-50°C / +100°C
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Drawings

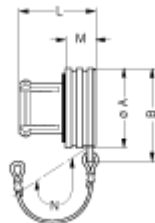

No keying

Dimensions

	A	B	L	M	N
mm.	10	12.5	11	4.8	85
in.	0.39	0.49	0.43	0.19	3.35

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/brd-0b-200-pcsg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.