

Special



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

---

[unipole multipole](#)

Size	00
------	----

[https://www.lemo.com/int\\_en/bre-00-200-cas.html](https://www.lemo.com/int_en/bre-00-200-cas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	No keying
Colour	Grey
Weight	2.17 g

## Environment

Environmental sealing (IP rating)	IP61
Temperature range	-50°C / +135°C
Salt Spray Corrosion	>1000 hr

## Drawings

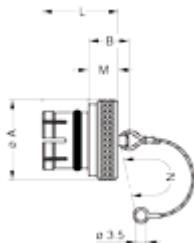

No keying

## Dimensions

	<b>A</b>	<b>B</b>	<b>L</b>	<b>M</b>	<b>N</b>
mm.	8	7.5	8.8	3.5	60
in.	0.31	0.3	0.35	0.14	2.36

[https://www.lemo.com/int\\_en/bre-00-200-cas.html](https://www.lemo.com/int_en/bre-00-200-cas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.