

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

SE series

Size	0S
Series	S - Indoor Stepped Insert

Technical details


Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) collet and crimping tube, brass (chrome plated [SAE AMS 2460]) collet nut
Keying	No keying
Colour	Grey
Weight	4.14 g

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP61
Temperature range	-50°C / +135°C
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

Drawings

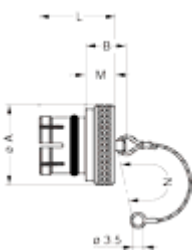

No keying

Dimensions

	A	B	L	M	N
mm.	10	9.5	10.5	4.5	85
in.	0.39	0.37	0.41	0.18	3.35

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/bre-0s-200-nas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.