

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[Coax triax mixed en](#)

Size	1K
Series	K - Outdoor keyed

Technical details


Form & Material

Shell style / Model id	BRF - Cap for free receptacle
Housing material	POM (black Polyoxymethylene) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	No keying
Weight	3.09 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

Drawings

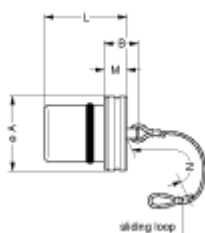

No keying

Dimensions

	A	B	L	M	N
mm.	17	12	20	6	85
in.	0.67	0.47	0.79	0.24	3.35

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/brf-1k-203-baz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.