

*Image for illustrative purpose only*

Summary

[Request a quote](#)[SE series](#)

Size	1S
Series	S - Indoor Stepped Insert

Technical details


Form & Material

Shell style / Model id	BRR - Cap spring loaded dust cap for ERA,ERN and EG receptacle or PSA and PK fixed receptacle
Housing material	PSU(Polysulfone) shell without treatment, FKM (VITON®)
Keying	Circular, female
Colour	Blue
Weight	1.05 g

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP61
Temperature range	-50°C / +150°C
Axes material	Nickel-plated brass
Maximum operating temperature	100°C
Watertightness	IP61 according to IEC 60529

Drawings

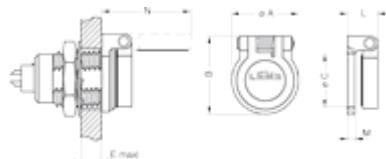

Dimensions

	A	B	C	E	L	M	N
mm.	14.2	17.1	12	6	6.3	1.5	20.3
in.	0.56	0.67	0.47	0.24	0.25	0.06	0.8

https://www.lemo.com/int_en/catalog/product/view/id/410811/s/brr-1s-200-pzva/category/38/

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.