

**Special***Image for illustrative purpose only*

## Summary

[Request a quote](#)**SE series**

Size	3S
Series	S - Indoor Stepped Insert

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/brr-3s-200-pzvn.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/brr-3s-200-pzvn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Footprint IPC Class3 compatibility	No
------------------------------------	----


## Form & Material

Shell style / Model id	BRR - Cap spring loaded dust cap for ERA,ERN and EG receptacle or PSA and PK fixed receptacle
Housing material	PSU(Polysulfone) shell without treatment, FKM (VITON®)
Keying	Circular, female
Colour	Black
Weight	3.1 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP61
Temperature range	-50°C / +150°C
Axes material	Nickel-plated brass
Maximum operating temperature	100°C
Watertightness	IP61 according to IEC 60529

## Drawings

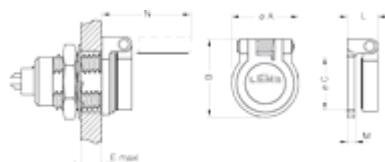

## Dimensions

	<b>A</b>	<b>B</b>	<b>C</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>N</b>
mm.	22.5	26.5	18.2	9	8.8	2.5	30.8
in.	0.89	1.04	0.72	0.35	0.35	0.1	1.21

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/brr-3s-200-pzvn.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/brr-3s-200-pzvn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.