

Standard

*Image for illustrative purpose only*

Summary

[Request a quote](#)

BKT series

Wire Size/AWG	36 - 28
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Panel Drill Hole	M9
Jacket cable outside diameter [mm]	1.00 - 8.30 mm
Size	0T
Suggested matching part	FGG.0T.312.CLAC50Z
Series	T - Small Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/eeg-0t-312-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

R (max) - electrical contact resistance	8.7 mOhm
Rated current	1.7 A
Test voltage contact-contact	1.1 kV DC
Test voltage contact-shell	1.5 kV DC
Max. Solid Conductor	0.09 mm ² (AWG 28)
Max. Stranded Conductor	0.05 mm ² (AWG 30)
Bucket Dia.	0.4 mm (0.016 in)
Contact Dia.	0.35 mm (0.014 in)
Wire Size/AWG	36 - 28
Gender	Standard

Form & Material

Shell style / Model id	EE - Fixed receptacle, nut fixing, back panel mounting
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	0.05 g
Panel Drill Hole	M9

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/eeg-0t-312-cll.html



LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Jacket cable outside diameter [mm]

1.00 - 8.30 mm

Drawings

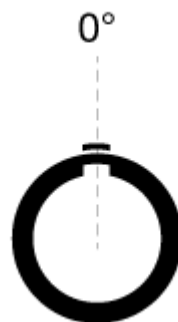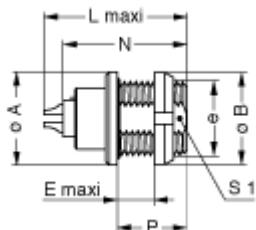

Dimensions

	A	B	e	E	Lmax	Nmax	S1	P
mm.	12	12	M9x0.6	6.5	21	19.1	8.2	9
in.	0.47	0.47		0.26	0.83	0.75	0.32	0.35

Recommended By Lemo

Caps

Compatible cap [BRE.0T.200.CAZ](#)

Soft Cap [BEZ.0B.200.SCN](#)

Tools

Spanner 2 [DCM.65.106.AZ4](#)

Spanner wrench [Socket for torque wrench DCM.0S.M09.4](#)

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/eeg-0t-312-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.12.T28.054PGZE		grey	
CMN.12.T28.054PNZE			
112280	PVC	Black	
12050	PVC	Black	
124080	PVC	Grey	
124084	PVC	Black	

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/eeg-0t-312-cll.html

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.