

Standard

*Image for illustrative purpose only*

Summary

[Request a quote](#)

BKT series

Number of contacts Low Voltage	16
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Panel Drill Hole	M15
Size	2T
Suggested matching part	FGG.2T.316.CLAC60
Series	T - Small Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/eeg-2t-316-clv.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	16
Contact Termination Low voltage	PCB - Elbow
R (max) - electrical contact resistance	6.1 mOhm
Insert configuration value	2T.316 - 16 Low Voltage
Footprint IPC Class3 compatibility	Yes
Class3 Productibility Level Compatibility	A (General Design Producibility - Preferred)
Insulator	L: PEEK (UL 94 / V-0/1.5)
Test voltage contact-contact	1.4 kV DC
Test voltage contact-shell	1.8 kV DC
Contact Dia.	0.7 mm (0.028 in)
Gender	Standard

Form & Material

Shell style / Model id	EE - Fixed receptacle, nut fixing, with elbow contacts for printed circuit (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	16.06 g
Panel Drill Hole	M15




https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/eeg-2t-316-clv.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Drawings

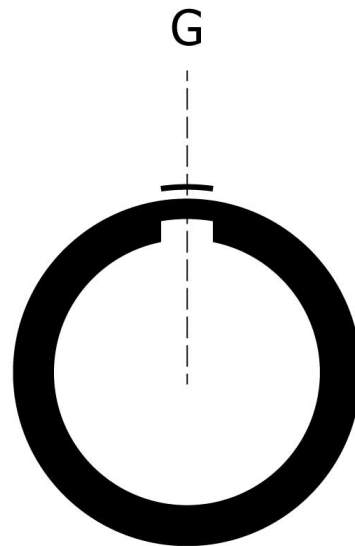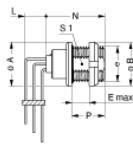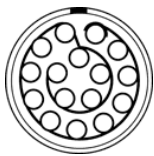

Dimensions

	A	B	e	E	Lmax	N	S1	P
mm.	18.5	20	M15x1.0	7.5	39.24	21.5	13.5	11
in.	0.73	0.79		0.3	1.54	0.85	0.53	0.43

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/eeg-2t-316-clv.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Caps	
Compatible cap	BRE.2T.200.CAZ
Soft Cap	BEZ.2B.200.SCN
Tools	
Spanner 2	DCM.65.176.AZ6
Spanner wrench	Socket for torque wrench DCM.2S.M15.6