

Special

*Image for illustrative purpose only*

Summary

[Request a quote](#)

BKT series

Number of contacts Low Voltage	7
Wire Size/AWG	34 - 28
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Panel Drill Hole	M9
Jacket cable outside diameter [mm]	1.00 - 8.30 mm
Size	0T
Suggested matching part	FGG.0T.307.KLAC50 FGG.0T.307.KLAK50Z
Series	T - Small Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/egg-0t-307-kll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	7
Contact Termination Low voltage	Solder
R (max) - electrical contact resistance	8.7 mOhm
Insert configuration value	T.307 - 7 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	3 A
Test voltage contact-contact	1.1 kV DC
Test voltage contact-shell	1 kV DC
Max. Solid Conductor	0.09 mm ² (AWG 28)
Max. Stranded Conductor	0.09 mm ² (AWG 28)
Bucket Dia.	0.45 mm (0.018 in)
Contact Dia.	0.5 mm (0.0197 in)
Wire Size/AWG	34 - 28
Gender	Standard

Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Black
Weight	4.96 g
Panel Drill Hole	M9

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/egg-0t-307-kl.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Jacket cable outside diameter [mm]	1.00 - 8.30 mm
------------------------------------	----------------

Drawings

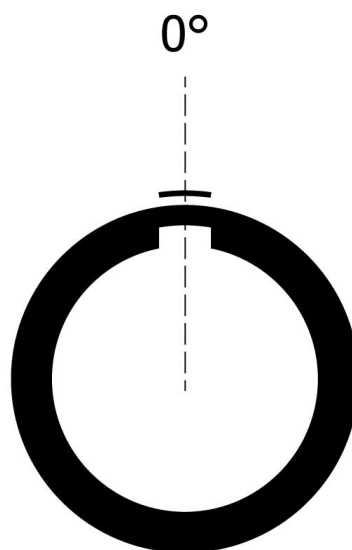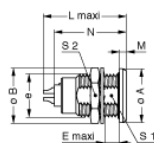

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/egg-0t-307-kl.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	e	E	L	M	N	S1	S2
mm.	12	12.5	M9x0.6	6	21	1.5	19.1	8.2	11
in.	0.47	0.49		0.24	0.83	0.06	0.75	0.32	0.43

Recommended By Lemo

Caps

Compatible cap [BRE.0T.200.KAZ](#)

Soft Cap [BEZ.0B.200.SCN](#)

Tools

Spanner [DCA.91.161.1TN](#)

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.07.T28.044PGZE		grey	
CMN.07.T28.044PNZE			
7041	PVC	Grey	
7050	PVC	Black	
717920	PVC	Grey	
CTR.75.030.121875G	PVC	Grey	

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/egg-0t-307-kl.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.