

[Standard](#)

Image for illustrative purpose only

Summary

[Request a quote](#)

BKT series

Number of contacts Low Voltage	19
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Panel Drill Hole	M15
Jacket cable outside diameter [mm]	1.00 - 12.60 mm
Size	2T
Suggested matching part	FGG.2T.319.CLAC50 FSG.2T.319.CLAC85
Series	T - Small Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/egg-2t-319-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	19
Contact Termination Low voltage	Solder
R (max) - electrical contact resistance	6.1 mOhm
Insert configuration value	T.319 - 19 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	5 A
Test voltage contact-contact	1.4 kV DC
Test voltage contact-shell	1.8 kV DC
Max. Solid Conductor	0.34 mm ² (AWG 22)
Max. Stranded Conductor	0.34 mm ² (AWG 22)
Bucket Dia.	0.8 mm (0.031 in)
Contact Dia.	0.7 mm (0.028 in)
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	9.96 g
Panel Drill Hole	M15

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/egg-2t-319-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.




Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Jacket cable outside diameter [mm]	1.00 - 12.60 mm
------------------------------------	-----------------

Drawings

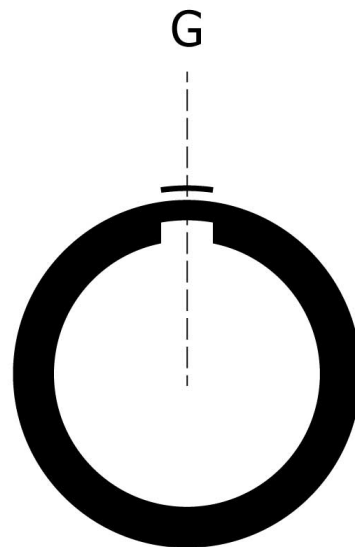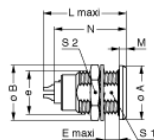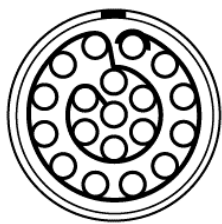

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/egg-2t-319-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	e	E	L	M	N	S1	S2
mm.	18.5	19.6	M15x1.0	13.5	23.6	1.8	24.6	13.5	17
in.	0.73	0.77		0.53	0.93	0.07	0.97	0.53	0.67

Recommended By Lemo

Caps

Compatible cap	BRE.2T.200.CAZ
----------------	--------------------------------

Soft Cap	BEZ.2B.200.SCN
----------	--------------------------------

Tools

Spanner	DCA.91.231.7TN
---------	--------------------------------

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.19.T22.079QGZE	TPR (medical)	Grey	

https://www.lemo.com/int_en/solutions/originals/t-small-outdoor-keyed/egg-2t-319-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.