

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

BKT series

Number of contacts Low Voltage	12
Number of contacts High Voltage	1
Wire Size/AWG	24 - 20
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 16.60 mm
Size	3B
Suggested matching part	FGG.3B.712.CJCD12
Series	B - Indoor keyed

Technical details

Electrical Configuration

Number of contacts Low Voltage	12
Contact Termination Low voltage	Crimp
Number of contacts High Voltage	1
Contact Termination High voltage	Solder
Insert configuration value	3B.712 - 1 High V. 12 Low V.
Footprint IPC Class3 compatibility	No
Insulator	J: PEEK/PEEK
Rated current	3 A
Rated current HV (A)	4
Rated current LV (A)	5
Test voltage HV Ue (kV dc)	12
Test voltage HV Ue (kV rms)	8.5
Test voltage LV cont-cont sold.(kV rms)	1.2
Test voltage LV cont-shell sold.(kV rms)	0.85
Contact Dia.	0.9
Wire Size/AWG	24 - 20
Gender	Standard

Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	27.06 g

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-3b-712-cjm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Jacket cable outside diameter [mm]	2.00 - 16.60 mm
------------------------------------	-----------------

Drawings

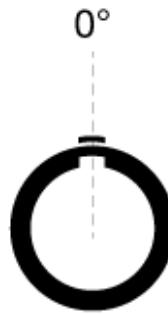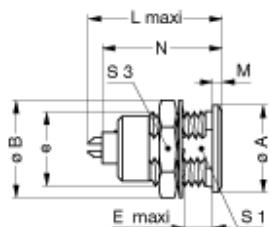

Dimensions

	A	B	e	E	L	M	N	S3	S1
mm.	22	25	M18x1.0	11.5	30.7	2	28.1	22	16.5
in.	0.87	0.98		0.45	1.21	0.08	1.11	0.87	0.65

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-3b-712-cjm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Replacement contact EGG.3B.660.ZZM

Compatible cap BRE.3S.200.NAS

Tools

Spanner DCA.91.282.2TN

Positionner DCE.91.093.BVM

Extraction tool DCC.09.05B.LAG

Crimp tool DPC.91.701.V

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-3b-712-cjm.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.