

Standard



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Coax	2
Wire Size/AWG	24 - 20
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 22.60 mm
Size	3K
Series	K - Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-846-clm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	2
Contact Termination Coax - Conductor fixing	Crimp
Contact Termination Coax - Screen fixing	Crimp
R (max)	5.8 mOhm
Insert configuration value	3K.846 - 2 Coax (50 Ohm), 6 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 A
Impedance	50 Ohms
Test voltage (kV DC)	1.3
Max. Conductor	0.34 mm ² (AWG 22)
Min. Conductor	0.34 mm ² (AWG 22)
Cable type	RG 174 A/U, RG 188 A/U, RG 316 /U
Contact Dia.	0.7 mm (0.03in)
Wire Size/AWG	24 - 20
Gender	Standard

Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	70.86 g

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-846-clm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.




Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Jacket cable outside diameter [mm]	2.00 - 22.60 mm
------------------------------------	-----------------

Drawings

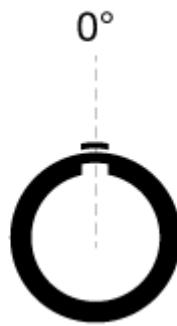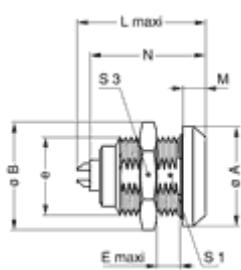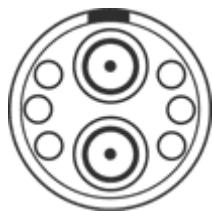

Dimensions

	e	E	L	M	N	S1	S3	A	B
mm.	M24x1.0	11	36.2	6	33.6	22.5	30	31	34.5
in.		0.43	1.43	0.24	1.32	0.89	1.18	1.22	1.36

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-846-clm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Replacement contact EGG.3B.660.ZZM

Compatible cap BRE.3K.200.NAS

Tools

Die Tool DPE.99.103.8K

Positionner DCE.91.093.BVM

Extraction tool DCC.09.05B.LAG

Crimp tool DPC.91.701.V

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-846-clm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.