

Special

*Image for illustrative purpose only*

Summary

[Request a quote](#)

BKT series

Number of contacts Low Voltage	30
Wire Size/AWG	20 - 18
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Panel Drill Hole	M35
Jacket cable outside diameter [mm]	4.00 - 33.60 mm
Size	5B
Suggested matching part	FGG.5B.330.CYCD13Z
Series	B - Indoor keyed

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-5b-330-cym.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	30
Contact Termination Low voltage	Crimp
R (max) - electrical contact resistance	3.6 mOhm
Insert configuration value	5B.330 - 30 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	8 A
Test voltage contact-contact	2.9 kV DC
Test voltage contact-shell	3.5 kV DC
Contact retention	40 N
Max. Conductor	1 mm ² (AWG 18)
Min. Conductor	0.5 mm ² (AWG 20)
Bucket Dia.	1.4 mm (0.055 in)
Contact Dia.	1.3 mm (0.051 in)
Wire Size/AWG	20 - 18
Gender	Standard

Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	136 g
Panel Drill Hole	M35

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-5b-330-cym.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.




Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr
Cable fixation	
Jacket cable outside diameter [mm]	4.00 - 33.60 mm

Drawings

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-5b-330-cym.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

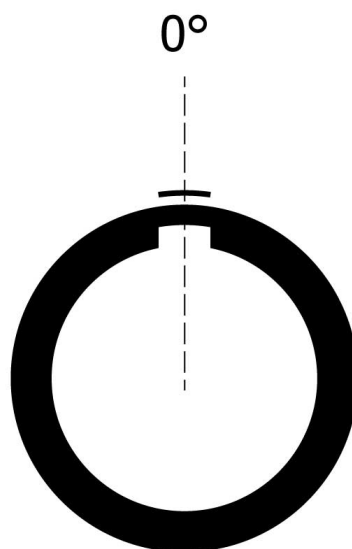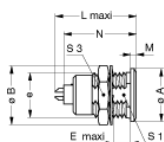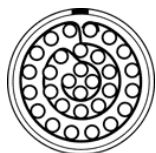

Dimensions

	e	E	L	M	N	S1	B	A
mm.	M35x1.0	11	43.5	3	39.6	33.5	40	40
in.		0.43	1.71	0.12	1.56	1.32	1.57	1.57

Recommended By Lemo

Contacts

Replacement contact [EGG.5B.665.ZZM](#)

Caps

Compatible cap [BRE.5S.200.NAS](#)

Cap 2 [BRE.5S.200.NAV](#)

Tools

Positionner [DCE.91.135.BVM](#)

Extraction tool [DCC.13.15B.LAG](#)

 
Crimp tool [DPC.91.701.V](#)

Spanner wrench [Socket for torque wrench DCM.65.370.AZ](#)

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-5b-330-cym.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.30.T22.087PGCE	PVC	GREY	
CMN.30.T22.087PGZE		grey	
CMN.30.T22.087PNCE	PVC	Black	
CMN.30.T22.087PNZE			
330240	PVC	Black	
330260	PVC	Black	
430250	PVC	Grey	

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-5b-330-cym.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.