

Special

*Image for illustrative purpose only*

Summary

[Request a quote](#)[Coax triax mixed en](#)

Nb of contacts Coax	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Panel Drill Hole	M24
Jacket cable outside diameter [mm]	2.60 - 22.60 mm
Size	3E
Suggested matching part	FFA.3E.250.KTAC11
Series	E - Outdoor Stepped Insert

Technical details

Electrical Configuration

Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Solder
Insert configuration value	3E.250 - 1 Coax (50 Ohm)
Insulator	T: PTFE
Rated current	26 A
Impedance	50 Ohms
VSWR	1.06 + 0.5 * f/GHz
Vtest	3000 V (AC), 4200 V (DC)
Cable type	RG 213/U, RG 115 A/U, RG 11 A/U, RG 144/U, RG 165 /U

Form & Material

Shell style / Model id	ERA - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (black chrome) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, female
Colour	Black
Weight	65.99 g
Panel Drill Hole	M24

Environment


Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Jacket cable outside diameter [mm]	2.60 - 22.60 mm
------------------------------------	-----------------

Drawings

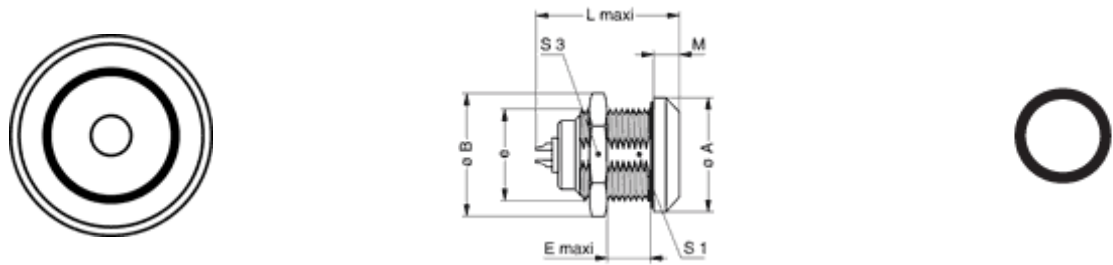

Dimensions

	A	B	e	E	L	M	S1	S3
mm.	31	34	M24x1.0	11	34	6	22.5	30
in.	1.22	1.34		0.43	1.34	0.24	0.89	1.18

Recommended By Lemo

Caps

Compatible cap	BRE.3K.200.NAS
----------------	--------------------------------

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.