

Standard

*Image for illustrative purpose only*

Summary

[Request a quote](#)[SE series](#)

Number of contacts Low Voltage	14
Wire Size/AWG	30 - 22
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Panel Drill Hole	M24
Jacket cable outside diameter [mm]	2.60 - 22.60 mm
Size	3E
Suggested matching part	FFA.3E.314.CLAC10
Series	E - Outdoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/era-3e-314-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	14
Contact Termination Low voltage	Solder
R (max) - electrical contact resistance	4.8 mOhm
Insert configuration value	3E.314 - 14 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	7 A
Test voltage (kV DC)	2.1
Max. Solid Conductor	0.34 mm ² (AWG 22)
Bucket Dia.	0.8 mm (0.031 in)
Contact Dia.	0.9 mm (0.035 in)
Wire Size/AWG	30 - 22

Form & Material

Shell style / Model id	ERA - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Colour	Grey
Weight	65.75 g
Panel Drill Hole	M24

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/era-3e-314-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Jacket cable outside diameter [mm]	2.60 - 22.60 mm
------------------------------------	-----------------

Drawings

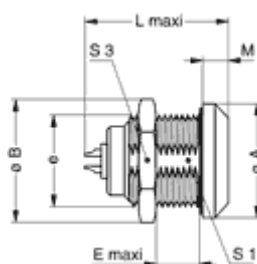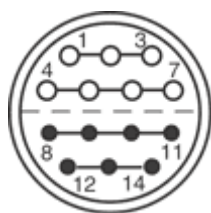

Dimensions

	A	B	e	E	L	M	S1	S3
mm.	31	34	M24x1.0	11	34	6	22.5	30
in.	1.22	1.34		0.43	1.34	0.24	0.89	1.18

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/era-3e-314-cll.html

 
LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Caps

Compatible cap	BRE.3K.200.NAS
Cap 2	BRE.3K.200.CAS

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.14.T22.068PGCE	PVC	GREY	
CMN.14.T22.068PGZE		grey	
CMN.14.T22.068PNCE	PVC	Black	
CMN.14.T22.068PNZE			
CMN.14.T28.056PGZE		grey	
CMN.14.T28.056PNZE			
CMN.14.T28.056QGZE	TPR (medical)	Grey	
114260	PTFE	White	
214140	PVC	Black	
214240	PTFE	White	
314250	PVC	Grey	

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/era-3e-314-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.