



Image for illustrative purpose only

## Summary

[Request a quote](#)

unipole multipole

Number of contacts Low Voltage	1
Wire Size/AWG	28 - 20
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.30 - 2.70 mm
Size	00
Suggested matching part	<a href="#">ERA.00.113.CTL</a> <a href="#">PCA.00.113.CTLC27</a>
Series	S - Indoor Stepped Insert

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-00-113-ctac27.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-00-113-ctac27.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	1
Contact Termination Low voltage	Solder
Insert configuration value	0.113 - 1 Low Voltage
Footprint IPC Class3 compatibility	No
Insulator	T: PTFE
Rated current	8 A
Test voltage (kV DC)	1.2
Contact Dia.	1.3
Wire Size/AWG	28 - 20

## Form & Material

Shell style / Model id	FFA - Straight plug with cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male
Colour	Grey
Weight	2.98 g

## Environment

Environmental sealing (IP rating)	IP50
Salt Spray Corrosion	>1000 hr


## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.30 - 2.70 mm

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-00-113-ctac27.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-00-113-ctac27.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

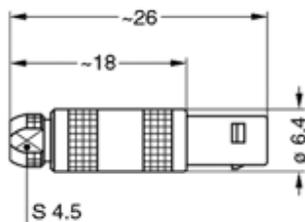

## Dimensions

	A	L	M
mm.	6.4	26	18
in.	0.25	1.02	0.71

## Recommended By Lemo

### Accessories

Compatible cap

[BFG.00.100.PCSG](#)

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-00-113-ctac27.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-00-113-ctac27.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.