

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

SE series

Number of contacts Low Voltage	2
Wire Size/AWG	18 - 10
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.10 - 5.00 mm
Size	4S
Suggested matching part	ERA.4S.302.SLL
Series	S - Indoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-302-slac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	2
Contact Termination Low voltage	Solder
Insert configuration value	4S.302 - 2 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	35 A
Test voltage (kV DC)	3
Bucket Dia.	3.7
Contact Dia.	4
Wire Size/AWG	18 - 10

Form & Material

Shell style / Model id	FFA - Straight plug, cable collet
Plug	Straight
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with male pin 1
Colour	Grey
Weight	138.46 g

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr


https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-302-slac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.10 - 5.00 mm

Drawings

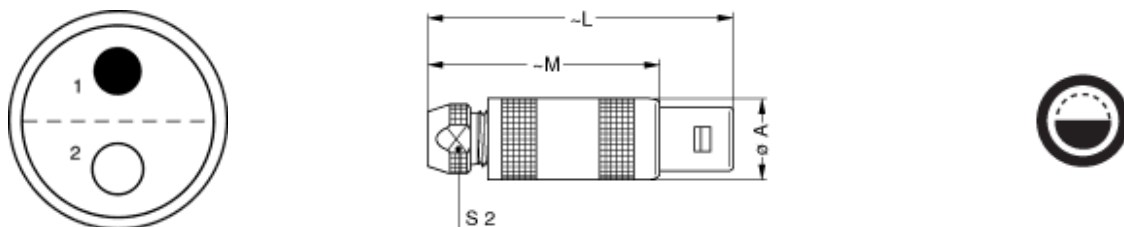

Dimensions

	A	M	S2	L
mm.	24.8	59	19	77
in.	0.98	2.32	0.75	3.03

Recommended By Lemo

Accessories









Compatible cap

[BFA.4S.100.NAS](#)

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-302-slac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.02.T20.047PGZE		grey	
CMN.02.T20.047PNZE			
CMN.02.T20.048QGZE	TPR (medical)	Grey	
120240	PVC	Black	
120250	PVC	Grey	
120501	PVC	Grey	
20260	PVC	Black	
2221	PVC	Black	
4082	PVC	Grey	

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-4s-302-slac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.