



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

high voltage connector Y S E 05 LEMO

Number of contacts High Voltage	1
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.30 - 5.70 mm
Size	3S
Suggested matching part	<a href="#">ERA.3S.410.CTL</a> <a href="#">PCA.3S.410.CTLC52</a>
Series	S - Indoor Stepped Insert

[https://www.lemo.com/int\\_en/catalog/product/view/id/529962/s/ffb-3s-410-ctac52/category/38/](https://www.lemo.com/int_en/catalog/product/view/id/529962/s/ffb-3s-410-ctac52/category/38/)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts High Voltage	1
Contact Termination High voltage	Solder
Insert configuration value	3S.410 - 1 High Voltage
Footprint IPC Class3 compatibility	No
Insulator	T: PTFE
Rated current	10 A
Test voltage (kV DC)	15
Creepage distance	16.5 mm

## Form & Material

Shell style / Model id	FFB - Straight plug, cable collet and safety locking ring
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male
Colour	Grey
Weight	62.74 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr



[https://www.lemo.com/int\\_en/catalog/product/view/id/529962/s/ffb-3s-410-ctac52/category/38/](https://www.lemo.com/int_en/catalog/product/view/id/529962/s/ffb-3s-410-ctac52/category/38/)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.30 - 5.70 mm

## Drawings

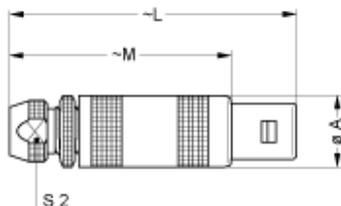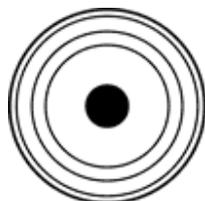

## Dimensions

	A	L	M	S2
mm.	17.8	75	60	14
in.	0.7	2.95	2.36	0.55

## Recommended By Lemo

### Accessories

Compatible cap [BFG.3B.100.PCSG](#)

### Tools

Spanner wrench [DCP.91.023.TN](#)

[https://www.lemo.com/int\\_en/catalog/product/view/id/529962/s/ffb-3s-410-ctac52/category/38/](https://www.lemo.com/int_en/catalog/product/view/id/529962/s/ffb-3s-410-ctac52/category/38/)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.