

Special

Image for illustrative purpose only

Summary

[Request a quote](#)

00and01Coaxial en

Nb of contacts Coax	1
Plug	Plug - Straight
Locking system	Snap-on
Jacket cable outside diameter [mm]	2.80 - 3.10 mm
Size	00
Suggested matching part	ERA.00.250.NTL
Series	00 - NIM-CAMAC

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fff-00-250-ntac31.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Solder
Contact Termination Coax - Screen fixing	Cable collet
R (max)	6.1 mOhm
Insert configuration value	0.25 - 1 Coax (50 Ohm)
Footprint IPC Class3 compatibility	No
Insulator	T: PTFE
Rated current	4 A
Impedance	50 Ohms
VSWR	1.09 + 0.11 * f/GHz
Vtest	2100 V (AC), 3000 V (DC)
Test voltage	2.1 kV (rms)
Cable type	RG 174 A/U
Bucket Dia.	0.6 mm (0.024in)
Contact Dia.	0.7 mm (0.028in)

Form & Material

Shell style / Model id	FFF - Straight plug, non-latching, with cable collet
Plug	Straight
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Snap-on
Keying	Circular, male
Colour	Grey
Weight	3.25 g

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fff-00-250-ntac31.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +260°C (max. temperature valid for short periods of use.)
F ret (min)	100 N
Salt Spray Corrosion	>144 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.80 - 3.10 mm

Drawings

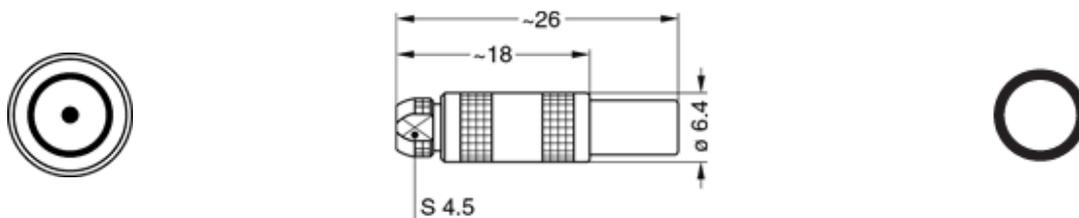

Dimensions

	M	L	A
mm.	18	26	6.4
in.	0.71	1.02	0.25

Cables

Cable PartNumber	Material	Colour	Cable image
17420	PVC	Black	
31600	PTFE	Brown	
CCX.50.RG1.74AU28N	PVC	Black	
CCX.50.RG1.74AU28N	PVC	Black	
CCX.50.RG3.16U28M	PTFE	Brown	

https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/fff-00-250-ntac31.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.