

Special

*Image for illustrative purpose only*

## Summary

[Request a quote](#)[SE series](#)

|                                    |                                                                     |
|------------------------------------|---------------------------------------------------------------------|
| Number of contacts Low Voltage     | 4                                                                   |
| Wire Size/AWG                      | 28 - 20                                                             |
| Plug                               | Plug - Straight                                                     |
| Locking system                     | Push-pull                                                           |
| Jacket cable outside diameter [mm] | 5.30 - 6.20 mm                                                      |
| Size                               | 2S                                                                  |
| Suggested matching part            | <a href="#">ERA.2S.304.CLL</a><br><a href="#">PCP.2S.304.CLLC62</a> |
| Series                             | S - Indoor Stepped Insert                                           |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffp-2s-304-clac62.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffp-2s-304-clac62.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

|                                 |                              |
|---------------------------------|------------------------------|
| Number of contacts Low Voltage  | 4                            |
| Contact Termination Low voltage | Solder                       |
| R (max)                         | 3.6 mOhm                     |
| Insert configuration value      | 2S.304 - 4 Low Voltage       |
| Insulator                       | L: PEEK (UL 94 / V-0/1.5)    |
| Rated current                   | 15 A                         |
| Test voltage (kV DC)            | 2.4                          |
| Max. Solid Conductor            | 0.5 mm <sup>2</sup> (AWG 20) |
| Max. Stranded Conductor         | 0.5 mm <sup>2</sup> (AWG 20) |
| Bucket Dia.                     | 1 mm (0.039in)               |
| Contact Dia.                    | 1.3 mm (0.051in)             |
| Wire Size/AWG                   | 28 - 20                      |

## Form & Material

|                        |                                                                                                                               |
|------------------------|-------------------------------------------------------------------------------------------------------------------------------|
| Shell style / Model id | FFP - Straight plug, cable collet and inner anti-rotating device                                                              |
| Plug                   | Straight                                                                                                                      |
| Housing material       | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system         | Push-pull                                                                                                                     |
| Keying                 | Hermaphroditic keying (half moon insert) with male pin 1                                                                      |
| Colour                 | Grey                                                                                                                          |
| Weight                 | 31.59 g                                                                                                                       |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffp-2s-304-clac62.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffp-2s-304-clac62.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

|                                   |                                                                         |
|-----------------------------------|-------------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Semiconductor, Test and Measurement |
| Environmental sealing (IP rating) | IP50                                                                    |
| Endurance                         | 5000 mating cycles                                                      |
| Temperature range                 | -55°C / +250°C (max. temperature valid for short periods of use.)       |
| Climatic Category                 | 55/175/21                                                               |
| Humidity (max)                    | <=95% [at 60 deg C /140 F]                                              |
| Shielding (min)                   | 75 dB (10 MHz)                                                          |
| Shielding (min)                   | 40 dB (1 GHz)                                                           |
| Shock Resistance                  | 100 g [ 6 ms]                                                           |
| Vibration                         | 15 g [10 Hz - 2000 Hz]                                                  |
| Salt Spray Corrosion              | >1000 hr                                                                |

## Cable fixation

|                                    |                                              |
|------------------------------------|----------------------------------------------|
| Cable termination protection       | Standard back nut (no additional protection) |
| Fixation type                      | Cable collet                                 |
| Jacket cable outside diameter [mm] | 5.30 - 6.20 mm                               |

## Drawings

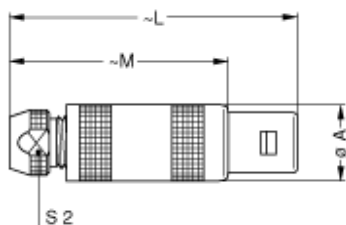

## Dimensions

|     | A    | L    | M    | S2   |
|-----|------|------|------|------|
| mm. | 14.8 | 52   | 40   | 11   |
| in. | 0.58 | 2.05 | 1.57 | 0.43 |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffp-2s-304-clac62.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffp-2s-304-clac62.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

## Caps

|                |                                 |
|----------------|---------------------------------|
| Compatible cap | <a href="#">BFG.2B.100.PCSG</a> |
| Plastic Cap    | <a href="#">BFG.2B.100.PCSG</a> |

## Cables

| Cable PartNumber   | Material      | Colour | Cable image                                                                          |
|--------------------|---------------|--------|--------------------------------------------------------------------------------------|
| CMN.04.T20.053PGZE |               | grey   |   |
| CMN.04.T20.053PNZE |               |        |   |
| CMN.04.T20.053QGZE | TPR (medical) | Grey   |   |
| 240500             | PVC           | Grey   |   |
| 4220               | PVC           | Black  |  |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffp-2s-304-clac62.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffp-2s-304-clac62.html)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.