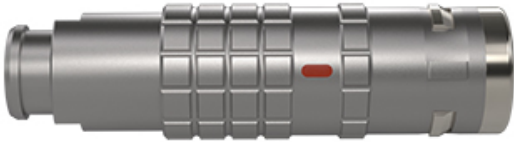


Standard



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

[Customer Drawing](#)

|                                    |                                |
|------------------------------------|--------------------------------|
| Number of contacts Low Voltage     | 3                              |
| Wire Size/AWG                      | 20 - 18                        |
| Gender                             | Standard                       |
| Plug                               | Plug - Straight                |
| Locking system                     | Push-pull                      |
| Jacket cable outside diameter [mm] | 4.10 - 4.50 mm                 |
| Size                               | 1K                             |
| Suggested matching part            | <a href="#">EGG.1K.303.CYM</a> |
| Series                             | K - Outdoor keyed              |

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-1k-303-cycc45z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-1k-303-cycc45z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

|                                 |                              |
|---------------------------------|------------------------------|
| Number of contacts Low Voltage  | 3                            |
| Contact Termination Low voltage | Crimp                        |
| R (max)                         | 3.6 mOhm                     |
| Insert configuration value      | 1K.303 - 3 Low Voltage       |
| Insulator                       | Y: PEEK for crimp contacts   |
| Rated current                   | 12 A                         |
| Vtest (contact-contact)         | 2.3 kV (DC)                  |
| Vtest (contact-shell)           | 2.6 kV (DC)                  |
| Contact retention               | 40 N                         |
| Max. Conductor                  | 1 mm <sup>2</sup> (AWG 18)   |
| Min. Conductor                  | 0.5 mm <sup>2</sup> (AWG 20) |
| Bucket Dia.                     | 1.4 mm (0.055in)             |
| Contact Dia.                    | 1.3 mm (0.051in)             |
| Wire Size/AWG                   | 20 - 18                      |
| Gender                          | Standard                     |

## Form & Material

|                        |                                                                                                                            |
|------------------------|----------------------------------------------------------------------------------------------------------------------------|
| Shell style / Model id | FG - Straight plug, cable collet and nut for fitting a bend relief                                                         |
| Plug                   | Straight                                                                                                                   |
| Housing material       | Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces |
| Locking system         | Push-pull                                                                                                                  |
| Keying                 | G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)                                                       |
| Colour                 | Grey                                                                                                                       |
| Variant                | Nut for fitting a bend relief                                                                                              |
| Weight                 | 24.45 g                                                                                                                    |

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-1k-303-cycc45z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-1k-303-cycc45z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Environment

|                                   |                                                                   |
|-----------------------------------|-------------------------------------------------------------------|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Test and Measurement |
| Environmental sealing (IP rating) | IP68                                                              |
| Endurance                         | 5000 mating cycles                                                |
| Temperature range                 | -55°C / +200°C (max. temperature valid for short periods of use.) |
| Climatic Category                 | 50/175/21                                                         |
| Humidity (max)                    | <=95% [at 60 deg C /140 F]                                        |
| Shielding (min)                   | 95 dB (10 MHz)                                                    |
| Shielding (min)                   | 80 dB (1 GHz)                                                     |
| Shock Resistance                  | 100 g [ 6 ms]                                                     |
| Vibration                         | 15 g [10 Hz - 2000 Hz]                                            |
| Salt Spray Corrosion              | >1000 hr                                                          |

## Cable fixation

|                                    |                       |
|------------------------------------|-----------------------|
| Cable termination protection       | For cable bend relief |
| Fixation type                      | Cable collet          |
| Jacket cable outside diameter [mm] | 4.10 - 4.50 mm        |

# Recommended By Lemo

## Accessories

|                     |                                |
|---------------------|--------------------------------|
| Replacement contact | <a href="#">FGG.1B.565.ZZC</a> |
| Compatible cap      | <a href="#">BFG.1K.100.NAS</a> |

## Tools

|                 |                                  |
|-----------------|----------------------------------|
| Positionner     | <a href="#">DCE.91.131.BVC</a>   |
| Extraction tool | <a href="#">DCC.13.15B.LAG</a>   |
| Crimp tool      | <a href="#">DPC.91.701.V</a>     |
| Spanner wrench  | <a href="#">DCD.1E.ZZZ.PA090</a> |

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-1k-303-cycc45z.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-1k-303-cycc45z.html)

 
 
LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Documents

Eplan

Download

# Cables

| Cable PartNumber | Material | Colour | Cable image                                                                         |
|------------------|----------|--------|-------------------------------------------------------------------------------------|
| 130250           | PVC      | Grey   |  |
| 30260            | PVC      | Black  |  |
| 3280             | PVC      | Black  |  |