

Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	18
Plug	Plug - Straight
Locking system	Push-pull
Size	2G
Suggested matching part	EGG.2G.318.CLL PHG.2G.318.CLLD52

Technical details

Electrical Configuration

Number of contacts Low Voltage	18
Contact Termination Low voltage	Solder
Insert configuration value	2G.318 - 18 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	5.5 A
Vtest (contact-contact)	1400 V (AC), 2000 V (DC)
Vtest (contact-shell)	1400 V (AC), 2000 V (DC)

Form & Material

Shell style / Model id	FGG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Weight	14.48 g

Environment

Environmental sealing (IP rating)	IP50
Endurance	500 mating cycles
Salt Spray Corrosion	>1000 hr


Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

Drawings

https://www.lemo.com/int_en/fgg-2g-318-clad52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

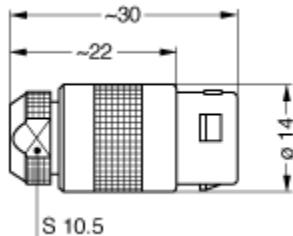

Dimensions

A	L	M	S2
mm.	14	30	22
in.	0.55	1.18	0.87