



Image for illustrative purpose only

Summary

[Request a quote](#)

[unipole](#) [multipole](#)

Number of contacts Low Voltage	18
Plug	Plug - Straight
Locking system	Push-pull
Size	2G
Suggested matching part	EGG.2G.318.CLL PHG.2G.318.CLLD72Z

https://www.lemo.com/int_en/fgg-2g-318-clad72z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	18
Contact Termination Low voltage	Solder
Insert configuration value	2G.318 - 18 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	5.5 A
Vtest (contact-contact)	1400 V (AC), 2000 V (DC)
Vtest (contact-shell)	1400 V (AC), 2000 V (DC)

Form & Material

Shell style / Model id	FGG - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Variant	Nut for fitting a bend relief
Weight	15.41 g

Environment

Environmental sealing (IP rating)	IP50
Endurance	500 mating cycles
Salt Spray Corrosion	>1000 hr


Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet

Drawings

https://www.lemo.com/int_en/fgg-2g-318-clad72z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

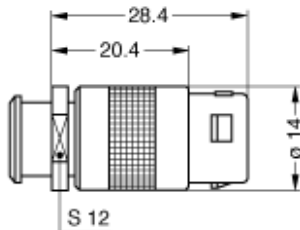

Dimensions

	A	L	M	S2
mm.	14	28.4	20.4	12
in.	0.55	1.12	0.8	0.47