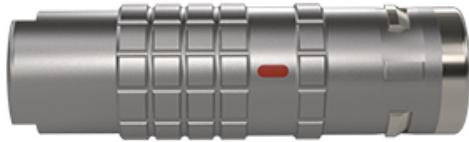


Standard

*Image for illustrative purpose only*

## Summary

[Request a quote](#)[BKT series](#)

Number of contacts Low Voltage	3
Wire Size/AWG	16 - 12
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	10.10 - 10.50 mm
Size	3K
Suggested matching part	<a href="#">EGG.3K.303.CYM</a>
Series	K - Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-3k-303-cycc11.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-303-cycc11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	3
Contact Termination Low voltage	Crimp
R (max)	3.3 mOhm
Insert configuration value	3K.303 - 3 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	25 A
Vtest (contact-contact)	4.5 kV (DC)
Vtest (contact-shell)	3.8 kV (DC)
Contact retention	65 N
Max. Conductor	2.5 mm <sup>2</sup> (AWG 12)
Min. Conductor	1.5 mm <sup>2</sup> (AWG 16)
Bucket Dia.	2.4 mm (0.094in)
Contact Dia.	2 mm (0.079in)
Wire Size/AWG	16 - 12
Gender	Standard

## Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-3k-303-cycc11.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-303-cycc11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.



## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	10.10 - 10.50 mm

## Drawings

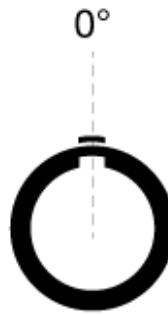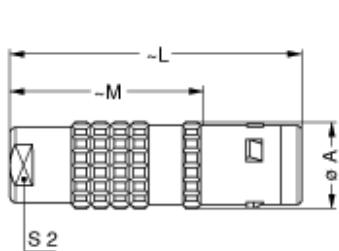

## Dimensions

A	L	S2	M
mm.	19	61	15
in.	0.75	2.4	0.59

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-3k-303-cycc11.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-303-cycc11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

## Accessories

---

Replacement contact **FGG.3B.575.ZZC**

Compatible cap **BFG.3K.100.NAS**

## Tools

---

Positionner **DCE.91.203.BVCM**

Extraction tool **DCC.20.25B.LAG**

Crimp tool **DPC.91.101.A**

Spanner wrench **DCD.3E.ZZZ.PA150**

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fgg-3k-303-cycc11.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-303-cycc11.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.