

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

[Coax triax mixed en](#)

Gender	Reverse Gender
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	10.60 - 12.00 mm
Size	3K
Series	K - Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgl-3k-8h2-cjmk111.html

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

R (max) - electrical contact resistance	5.8 mOhm
Insulator	J: PEEK/PEEK
Rated current	2 A
Max. Conductor	0.34 mm ² (AWG 22)
Min. Conductor	0.34 mm ² (AWG 22)
Contact Dia.	0.7 mm (0.028 in)
Gender	Reverse Gender

Form & Material

Shell style / Model id	FG - Straight plug with oversize cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	2 keys (gamma=75, plug: female contacts, receptacle: male contacts)
Colour	Grey
Weight	110.61 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatic Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr



https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgl-3k-8h2-cjmk111.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	10.60 - 12.00 mm

Drawings

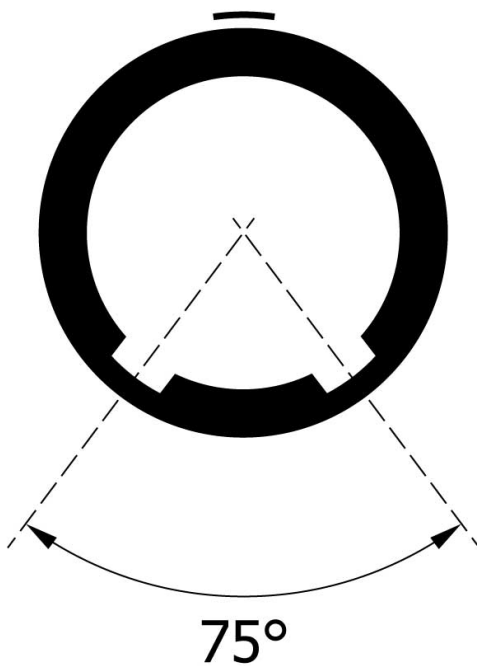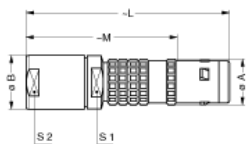

Dimensions

	M	L	B	S2	S1	A
mm.	65	85	22	19	19	19
in.	2.56	3.35	0.87	0.75	0.75	0.75

Recommended By Lemo

Contacts	
Replacement contact	EGG.3B.660.ZZM
Caps	
Compatible cap	BFL.3K.100.NAS
Cap 2	BFL.3K.100.NAV
Tools	
Die Tool	DPE.99.103.8K
Positionner	DCE.91.093.BVM
Extraction tool	DCC.09.05B.LAG
Spanner wrench	DCD.3E.ZZZ.PA150

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgl-3k-8h2-cjmk111.html

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.