

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

[M series](#)

[Application leaflet Security Defence](#)

Number of contacts Low Voltage	5
Wire Size/AWG	26 - 22
Gender	Reverse Gender
Plug	Plug - Straight
Locking system	Ratchet
Jacket cable outside diameter [mm]	4.00 - 8.00 mm
Size	0M
Suggested matching part	PMT.0M.305.LLCS HET.0M.305.LLDPS
Series	M - Rugged Ratchet coupling

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Number of contacts Low Voltage	5
Contact Termination Low voltage	Crimp
R (max)	6.1 mOhm
Insert configuration value	0M.305 - 5 Low Voltage
Insulator	L: PEEK
Rated current	6.5 A
Test voltage contact-contact	1.75 kV DC
Test voltage contact-shell	1.4 kV DC
Contact retention	22 N
Max. Conductor	0.34 mm² (AWG 22)
Min. Conductor	0.14 mm² (AWG 26)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Wire Size/AWG	26 - 22
Gender	Reverse Gender

Form & Material

Shell style / Model id	FG - Straight plug with arctic grip
Plug	Straight
Locking system	Ratchet
Keying	T: 3 keys (beta=135, gamma=90, plug: female contacts, receptacle: male contacts)
Colour	Orange
Weight	5.9 g




Environment

Technical domain	Motorsport, Security and Defence, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP68
Endurance	3000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
EMI Shielding EIA 364-66A	>= 80 dB (1 GHz), >=70 dB (3 GHz), >= 58 dB (6 GHz), >= 40 dB (10 GHz)
Gunfire vibration	25 Hz - 2000 Hz, 3 axis (Apache helicopter)
Humidity (max)	21 days at 95%
Lighting strike EIA 364-76	10K amps - 6 times
Shock Resistance	300 g [3 ms]
Thermal shock	5 cycles: -65°C to +150°C
Vibration-Random	37.8 g rms - 3 axes, 4 hr amb [50 Hz - 2000 Hz]
Vibration-Sine	30 g, 3 axes, 12 hr [10 Hz - 2000 Hz]

Cable fixation

Cable termination protection	Heatshrink
Fixation type	Heatshrink
Jacket cable outside diameter [mm]	4.00 - 8.00 mm

Drawings

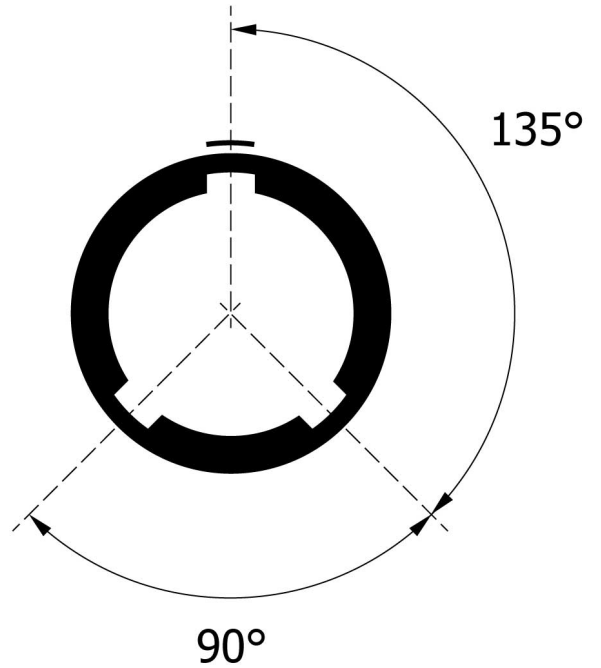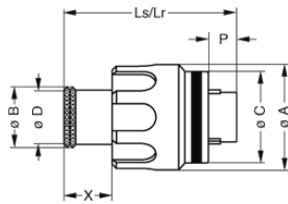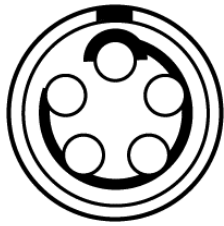

Dimensions

	A	B	C	D	Ls	Lr	P	X
mm.	14.4	8.8	12.7	8	24.1	24.1	3.9	6.7
in.	0.57	0.35	0.5	0.31	0.95	0.95	0.15	0.26

Recommended By Lemo

Contacts	
Replacement contact	EGN.0M.655.ZZM
Tools	
Positionner	DCE.91.070.3MVM
Extraction tool	DCC.07.04B.LAG
Insertion tool	DCV.07.05M.LA
Crimp tool	DPC.91.701.V

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.