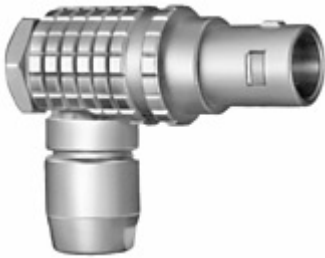


Special

*Image for illustrative purpose only*

Summary

[Request a quote](#)[BKT series](#)

Number of contacts Low Voltage	10
Wire Size/AWG	30 - 22
Gender	Standard
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	3.10 - 4.00 mm
Size	2B
Suggested matching part	EGG.2B.310.CLL
Alternative part	FPG.2B.310.CLAM42
Series	B - Indoor keyed

Technical details

Electrical Configuration

Number of contacts Low Voltage	10
Contact Termination Low voltage	Solder
R (max)	4.8 mOhm
Insert configuration value	2B.310 - 10 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	8 A
Vtest (contact-contact)	2 kV (DC)
Vtest (contact-shell)	1.9 kV (DC)
Max. Solid Conductor	0.34 mm² (AWG 22)
Max. Stranded Conductor	0.34 mm² (AWG 22)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.9 mm (0.035in)
Wire Size/AWG	30 - 22
Gender	Standard



Form & Material

Shell style / Model id	FH - Elbow plug, cable collet
Plug	Elbow
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr
Cable fixation	
Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	3.10 - 4.00 mm

Drawings

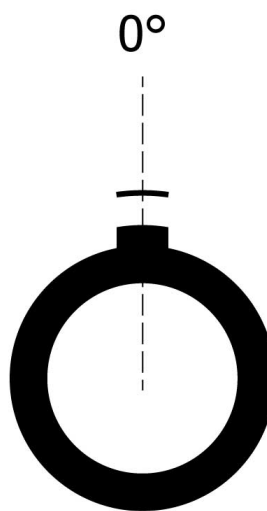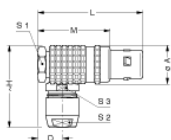

Dimensions

	A	D	H	L	M	S1	S2	S3
mm.	16.5	9	34	41.5	29.5	14	12	13
in.	0.65	0.35	1.34	1.63	1.16	0.55	0.47	0.51

Recommended By Lemo

Caps	
Compatible cap	BHY.2B.100.NAZ
Plastic Cap	BFG.2B.100.PCSG
Soft Cap	BFZ.2B.100.SCN

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.